

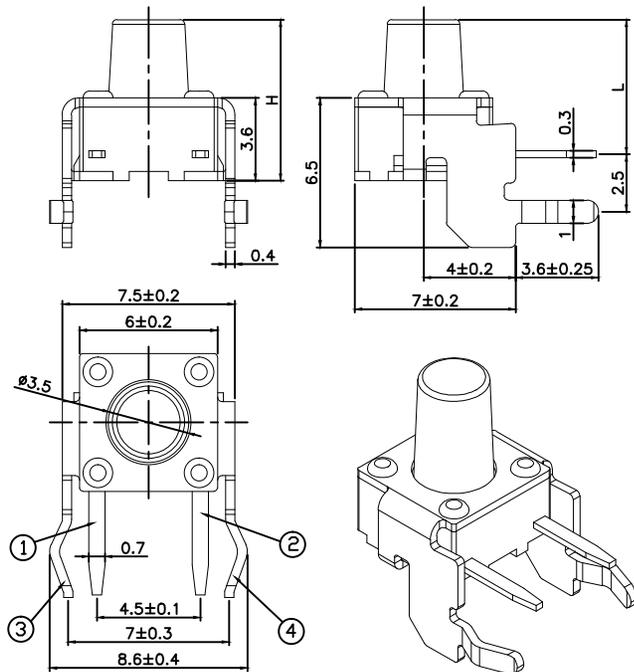
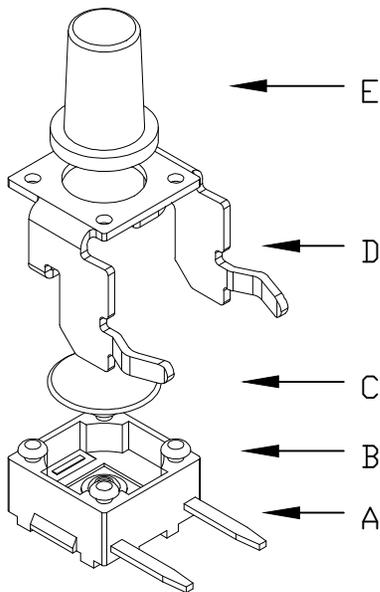


TSD020*****

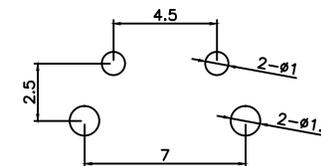

H	L
4.3	3.15
5.0	3.85
5.5	4.35
6.0	4.85
6.5	5.35
7.0	5.85
....

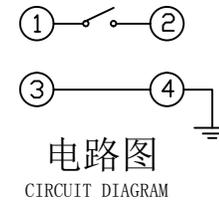

主要技术参数、性能

The Main Thchnology Performance

额定电流、电压 Rate voltage,current	50mA DC12V
接触电阻 Contact resistance	≤100mΩ
按力 Operating force	±50gf
行程 Travel	0.20±0.10mm
绝缘电阻 Insulated resistance	≥100MΩ
介电强度 Dielectric strength	≥250VAC/1min

T S D 0 2 0

寿命:
A: ≥30000次
B: ≥100000次
C: ≥200000次

高度H:
043: 4.3H
045: 4.5H
048: 4.8H
050: 5.0H
060: 6.0H
...
080: 8.0H

力度:
18: 180g
26: 260g


包装方式:
A: 散件
B: 冷封编带
C: 热封编带

特殊码

E	按钮	PPA	1	黑色
D	盖板	铁盖板	1	镀铜锡
C	弹片	磷铜/不锈钢	1	镀银
B	本体	PPA	1	黑色
A	卡件	黄铜	1	镀银
项目 ITEM	名称 DESCRIPTION	材质 MATERIAL	数量 QTY	表面处理/颜色 FINSH/COLOR

标记 SING	处数 FREQUENCY	更改文件号 REVISION	签名 APPROVED	日期 DATE	比例 SCALE	1:1	一般公差 GENERAL TOLERANCE
设计 DESIGN		朱元隆		2021.06.01	单位 UNIT	mm	≥0~2< ±0.10
审核 CHECKED		赵晓峰		2021.06.01	重量 WEIGHT		≥2~5< ±0.25
批准 APPROVED		陈乐峰		2021.06.01			≥5 角度 ANGLE ±0.30 ±0.5°

 第一视角
FIRST VIEW



名称/NAME:
轻触开关
TACTILE SWITCH

型号/MODEL:
TSD020*****

BZCN 浙江博众电气有限公司
ZHEJIANG BOZHONG ELECTRONIC CO., LTD.