

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0513383474](#)

Status: **Active**

Overview: [SlimStack Board-to-Board/Board-to-FPC Connectors](#)

Description: SlimStack Board-to-Board Receptacle, 0.40mm Pitch, J-Bend Series, 0.20µm Gold (Au) Plating, 1.50 or 2.00mm Mated Height, 3.40mm Mated Width, 34 Circuits

Documents:

[2D Drawing DXF \(PDF\)](#)

[2D Drawing \(DXF\)](#)

[Drawing \(PDF\)](#)

[3D Model \(PDF\)](#)

[3D Model](#)

[Product Specification PS-51338-002-001 \(PDF\)](#)

[Product Specification PS-51338-003-001 \(PDF\)](#)


[Packaging Specification SPK-51338-001-001 \(PDF\)](#)

[Datasheet \(PDF\)](#)

[Product Guide \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

[Reference Guide \(PDF\)](#)

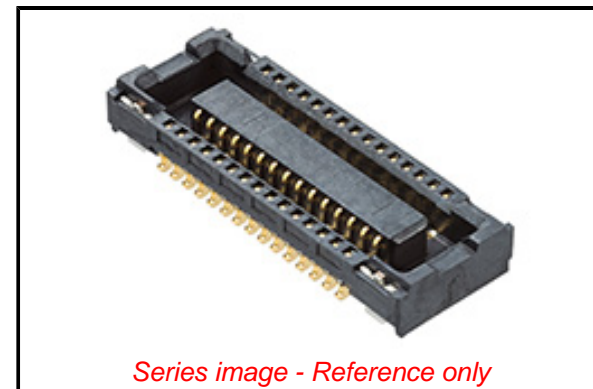

Series image - Reference only

General

Product Family	PCB Receptacles
Series	51338
Application	Board-to-Board, Signal
Comments	Solder Tab Plating: Tin (Sn) over Nickel
Overview	SlimStack Board-to-Board/Board-to-FPC Connectors
Product Name	SlimStack
Series Name	0.4, J-Bend
UPC	191128119719

Physical

Circuits (Loaded)	34
Circuits (maximum)	34
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Lock to Mating Part	Yes
Mated Height	1.50mm, 2.00mm
Mated Width	3.40mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	64.363/mg
Number of Rows	2
Orientation	Vertical
PCB Locator	No
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Plating min - Mating	0.200µm
Polarized to Mating Part	No
Polarized to PCB	No
Surface Mount Compatible (SMC)	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[51338 Series](#)

Mates With

[SlimStack J-Bend Plug 55909](#)

Packaging Specification
Product Specification
Sales Drawing

SPK-51338-001-001
PS-51338-002-001, PS-51338-003-001
SD-51338-003-001, SD-51338-004-001

This document was generated on 05/24/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION