

Specifications :


Voltage rating: 600V AC / DC
 Current rating: Table
 Withstanding voltage: 2200V AC/minute
 Temperature range: -40°C~+105°C
 Insulation resistance: ≥1000M Ω
 Contact resistance: ≤5mΩ
 After environmental testing: ≤10mΩ
 Material : High conductive Brass
 Wire Range:AWG#12
 Insulation O.D.: 1.85mm(Max)
 Plating method : Blank-Stamping before plating

X5700 T -PSN -H

- ① ② ③ ④ ⑤


- ① Series Number
- ② Category: T-terminal
- ③ Material: P-Phosphir bronze
- ④ Plating style:
SN-Bright tin plating 100u" Min Sn,Ni 50u"Min
- ⑤ Mold No./Mark/Special No.

H-Height (applicable to12 #)

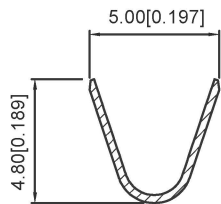


SECTION A-A
SCALE 1:1

CONDUCTOR CRIMP 12 AWG

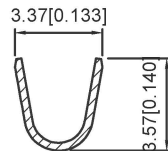

SECTION A-A
SCALE 1:1

CONDUCTOR CRIMP 14/16 AWG

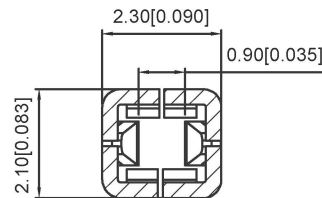

SECTION B-B
SCALE 2:1

Current rating				
Ckt. Size	2	4	6	8~12
AWG & Metric wire size	21A	18 A	16 A	14 A
12 AWG,4mm ²				

X5700T-PSN-H	High conductive Brass	X5700H	X5700W
PART NO	Material	Suitable XKB Terminal	Suitable XKB Terminal

广东星坤科技股份有限公司

生效	日期
文件	工程
MARK	章

DESCRIPTION	DATE	REVISED	APPROVED	UNSPECIFIED TOLERANCES

DSND		DATE		SCALE: N/A	MODEL TYPE: Wire to board connector
DWN		DATE		VIEW:	PART NO.:
CHKD		DATE		UNIT: mm/in	DWG NO.: X5700T-XX-X
APPD		DATE		SIZE: A4	
XKB INDUSTRIAL PRECISION CO., LIMITED					WEIGHT · SHEET · REVISION 1.0g 1/1 A0