


Specifications :

Voltage rating: 600V AC / DC
 Current rating: 23A AC / DC
 Withstanding voltage: 2200V AC/minute
 Temperature range: -40°C~+105°C
 Insulation resistance: ≥1000M Ω
 Contact resistance: ≤2mΩ
 After environmental testing : ≤10mΩ
 Plug the Pin & Special No.: H-High conductive Brass

X5700 W V -2xXX -LP SW
 ① ② ③ ④ ⑤ ⑥

- ① Series No.
- ② Category : W-WAFER
- ③ Welding Board Angle : V-Straight 180°
- ④ Row No.-Pin No.: 2xXX-2x02P~2x06P
- ⑤ Material: LP -LCP 94V-0
- ⑥ Plating Category: SW-Matte Tin Plating

Poles	Dimensions (mm)		
	AB		C
2x01	8.35	12.34	
2x02	12.05	5.70	16.04
2x03	17.75	11.40	21.74
2x04	23.45	17.10	27.44
2x05	29.15	22.80	33.14
2x06	34.85	28.50	38.84

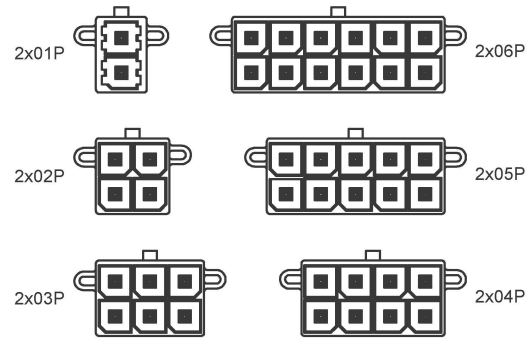

X5700WV-2xXX-LPSW	High conductive Brass	X5700H	X5700T
PART NO	Material	Suitable XKB Terminal	Suitable XKB Terminal

广东星坤科技股份有限公司

生	日期
ΔX	日期
ΔX	日期
ΔX	日期
MARK	文件工程章

units:	mm
tolerance:	
X.X	±0.2mm
X.XX	±0.1mm
X.XXX	±0.05mm
	UNSPECIFIED TOLERANCES

DSND	DATE	SCALE: N/A	MODEL TYPE: Wire to board connector
DWN	DATE	VIEW:	PART NO.:
CHKD	DATE	UNIT: mm/in	DWG NO.:
APPD	DATE	SIZE: A4	X5700WV-2xXX-LPSW
XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT · SHEET · REVISION 1.0g 1/1 A0