


A-A

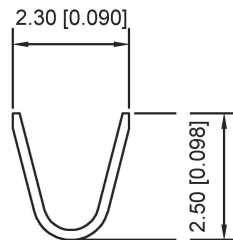

B-B

■ Specifications :

- Voltage rating: 250V AC / DC
- Current rating: 7A AC / DC
- Withstanding voltage: 1500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: $\geq 1000M \Omega$
- Contact resistance: $\leq 10m\Omega$
- After environmental testing : $\leq 20m\Omega$

X8672 T X-X SN X-B
① ② ③ ④ ⑤ ⑥ ⑦

- ① Series No
- ② Category :
T-Terminal
- ③ Welding Board Angle ;
Blank-Normal Leads
- ④ Material:
B-Brass
- ⑤ Plating Category:
SN-Bright Tin Plating (70-120u")
- ⑥ Plating Way:
Blank-Stamping before Plating
B-Plating before Stamping
- ⑦ Special No:
B-Match X8672H-XXB HSG

X8672T-BSN-B	Brass	AWG#18-24	2.80mm(Ma x)	Stamping Before Plating: 50u" MIN. Ni;70u" MIN. Sn	X8672H-B	10,000Pcs
X8672T-PSN-B	Phosphor Bronze					
PART NO	Material	Wire Range	Insulation O. D.	Finish	Suitable X K B Terminal	Qty/Rel1

广东星坤科技股份有限公司

生效

ΔX	日期
ΔX	日期
ΔX	日期
MARK	DESCRIPTION

REVISIONS

DATE	REVISED	APPROVED	UNSPECIFIED TOLERANCES
------	---------	----------	------------------------

DSND	DATE	SCALE: N/A	MODEL TYPE: X8672T-XXX-B
DWN	DATE	VIEW:	PART NO.: 3.96mm Crimp Style Connectors
CHKD	DATE	UNIT: mm/in	DWG NO.:
APPD	DATE	SIZE: A4	
XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT 1.0g
			SHEET 1/1
			REVISION A0

文件工程章

www.xk-dg.cn www.helloxkb.com www.helloxkb.cn