

■ Specifications :

- Voltage rating: 150V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: ≥500MΩ
- Contact resistance: ≤30mΩ
- After environmental testing: ≤40mΩ






X9812 H X-2*XX XX-N0 XX

① ② ③ ④ ⑤ ⑥ ⑦

- ① Series No.
- ② Category: H-HSG
- ③ Welding Board Angle: Blank-ordinary
- ④ Row No.-Pin No.: 2*XX-2*02P~2*25P
- ⑤ Plug the Pin & special No.: HF-Halogen free
- ⑥ Material: N0-PA66 94V-0
- ⑦ Color: Blank-natural color

Poles	Dimensions(mm)			Poles	Dimensions(mm)		
	A	B	C		A	B	C
2*02	1.25	6.70	4.20	2*13	15.00	20.45	17.95
2*03	2.50	7.95	5.45	2*14	16.25	21.70	19.20
2*04	3.75	9.20	6.70	2*15	17.50	22.95	20.45
2*05	5.00	10.45	7.95	2*16	18.75	24.20	21.70
2*06	6.25	11.70	9.20	2*17	20.00	25.45	22.95
2*07	7.50	12.95	10.45	2*18	21.25	26.70	24.20
2*08	8.75	14.20	11.70	2*19	22.50	27.95	25.45
2*09	10.00	15.45	12.95	2*20	23.75	29.20	26.70
2*10	11.25	16.70	14.20	2*21	25.00	30.45	27.95
2*11	12.50	17.95	15.45	2*25	30.00	35.45	32.95
2*12	13.75	19.20	16.70				

X9812H-2*XXHF-N0	Nylon 66 UL 94V-0 Halogen-Free	X9812T-L	X9812W
X9812H-2*XX-N0	Nylon 66 UL 94V-0		
PART NO	Material	Suitable XKB Terminal	Suitable XKB Terminal

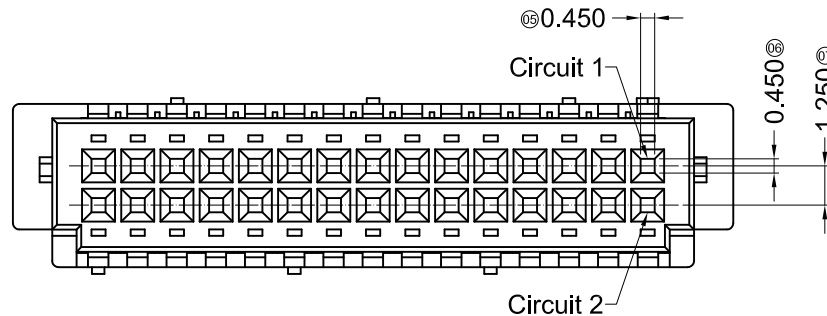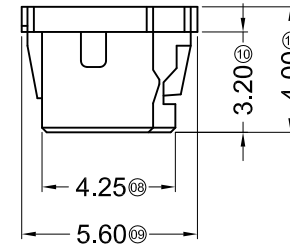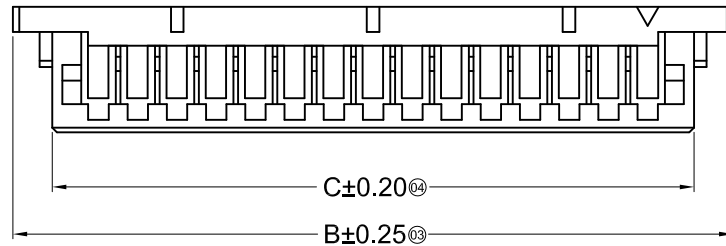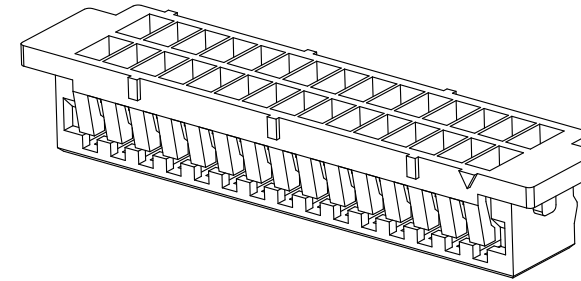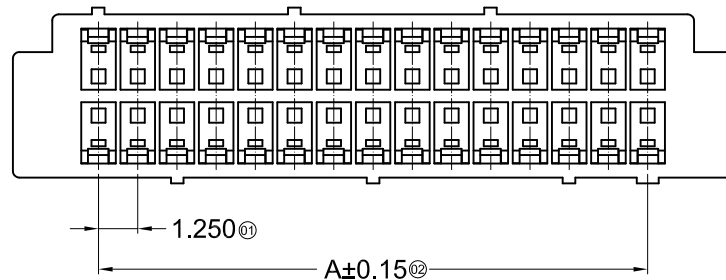

For and on behalf of
XKB INDUSTRIAL PRECISION CO., LIMITED
 香港星坤工業精密有限公司

△ X					ANGULAR	±5°
△ X					L ≤ 4	±0.2
△ X					4 < L ≤ 16	±0.3
△ X					16 < L ≤ 63	±0.4
MARK	DESCRIPTION	DATE	REVISED	APPROVED	L > 63	±0.5
REVISIONS					UNSPECIFIED TOLERANCES	

DSND	DATE	SCALE: N/A	MODEL TYPE: X9812H-2*XXHF-N0
DWN	DATE	VIEW:	PART NO.:
CHKD	DATE	UNIT: mm	1.25mm Crimp Style Connectors
APPD	DATE	SIZE: A4	DWG NO.:
XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT 1.0g
			SHEET 1/1
			REVISION A0