


■ Specifications :

- Voltage rating: 50 V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: ≥500MΩ
- Contact resistance: ≤20mΩ
- After environmental testing: ≤30mΩ

X1502 H-XX-N0

① ② ③ ④

- ① Series Number
- ② Category : H-HSG
- ③ Row No.Pin No:xx-02-15P
- ④ Material:N0-PA66 94V-0

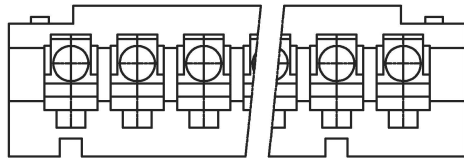

Poles	Dimensions(mm)		Poles	Dimensions(mm)	
	A	B		A	B
02	1.50	4.5	09	12.00	15.0
03	3.00	6.0	10	14.0	16.5
04	4.50	7.5	11	15.0	18.0
05	6.00	9.0	12	17.0	19.5
06	7.50	10.5	13	19.0	21.0
07	9.00	12.0	14	24.0	
08	10.50	13.5	15	24.0	

X1515H-XX-N0	PA66 UL 94V-0	X1502T	X1502W
PARTY NO	Material	Suitable XKB Terminal	Suitable XKB Terminal

广东星坤科技股份有限公司

生效

ΔX	日期
ΔX	日期
ΔX	日期
MARK	DESCRIPTION

REVISIONS	DATE	REVISED	APPROVED	UNSPECIFIED TOLERANCES

DSND	DATE	SCALE: N/A	MODEL TYPE: X1502H-XX-N0
DWN	DATE	VIEW:	PART NO.: 1.5mm Crimp Style Connectors
CHKD	DATE	UNIT: mm/in	DWG NO.:
APPD	DATE	SIZE: A4	
XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT 1.0g
			SHEET 1/1
			REVISION A0

文件工程章

www.xk-dg.cn www.helloxkb.com www.helloxkb.cn