



SEC:A-A

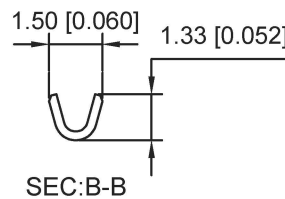

SEC:B-B

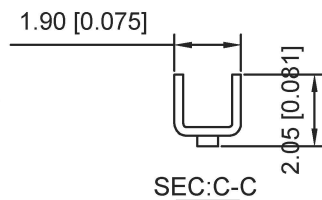

SEC:C-C

■ Specifications :

- Voltage rating: 250V AC / DC
- Current rating: 3A AC / DC
- Withstanding voltage: 800V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: $\geq 1000M \Omega$
- Contact resistance: $\leq 10m\Omega$
- After environmental testing : $\leq 20m\Omega$

X8826 T P- SN
① ② ③ ④

- ① Series Number.
- ② Category : Terminal
- ③ Material:P-Phosphor bronze
- ④ Plating style:SN-Bright tin Plating

X8826T-PSN	Phosphor Bronze	AWG#22-30	1.90mm(Max)	Stamping Before Plating 30u" Ni/70u" Sn	X8826H
PART NO	Material	Wire Range	Insulation O.D.	Finish	Suitable XKB Terminal

广东星坤科技股份有限公司

生效

ΔX	日期
ΔX	日期
ΔX	日期
MARK	DESCRIPTION

文件工程章

REVISIONS	DATE	REVISED	APPROVED	UNSPECIFIED TOLERANCES
-----------	------	---------	----------	------------------------

DSND	DATE	SCALE: N/A	MODEL TYPE: X8826T-PSN
DWN	DATE	VIEW:	PART NO.: 2.5mm Crimp Style Connectors
CHKD	DATE	UNIT: mm/in	DWG NO.: X8826T-PSN
APPD	DATE	SIZE: A4	
XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT 1.0g
			SHEET 1/1
			REVISION A0

www.xk-dg.cn www.helloxkb.com www.helloxkb.cn