




SECTION A-A
SCALE 1:1

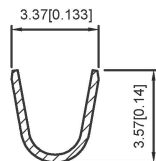

SECTION A-A
SCALE 1:1

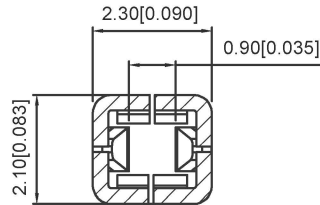

SECTION B-B
SCALE 2:1

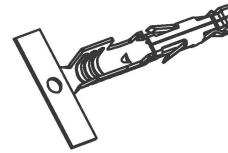

Specifications :

Voltage rating: 600V AC / DC
 Current rating: Table
 Withstanding voltage: 2200V AC/minute
 Temperature range: -40°C~+105°C
 Insulation resistance: ≥1000M Ω
 Contact resistance: ≤5mΩ
 After environmental testing : ≤10mΩ
 Material : High conductive Brass
 Wire Range:AWG#14-16
 Insulation O.D.: 1.85mm(Max)
 Plating method : Blank-Stamping before plating

X5700 T- PSN -L

① ② ③ ④ ⑤

- ① Series Number
- ② Category: T-terminal
- ③ Material: P-Phosphir bronze
- ④ Plating style:
SN-Bright tin plating 100u" Min Sn,Ni 50u"Min
- ⑤ Mold No./Mark/Special No.
L- Low foot (applicable to 14#/16 #)

AWG & Metric wire size	Current rating			
	2	4	6	8~12
14 AWG, 2.5mm ²	19 A	15 A	13 A	11 A
16 AWG, 1.5mm ²	15 A	13 A	11 A	10 A

	X5700T-PSN-L	High conductive Brass	X5700H	X5700W
PART NO		Material	Suitable XKB Terminal	Suitable XKB Terminal

广东星坤科技股份有限公司

生	日期
效	日期
效	日期
效	日期
MARK	文件工程章

DESCRIPTION	DATE	REVISED	APPROVED	UNSPECIFIED TOLERANCES

DSND		DATE		SCALE: N/A	MODEL TYPE: Wire to board connector
DWN		DATE		VIEW:	PART NO.:
CHKD		DATE		UNIT: mm/in	DWG NO.: X5700T-XX-X
APPD		DATE		SIZE: A4	
KKB INDUSTRIAL PRECISION CO., LIMITED					WEIGHT · SHEET · REVISION 1.0g · 1/1 · A0