
 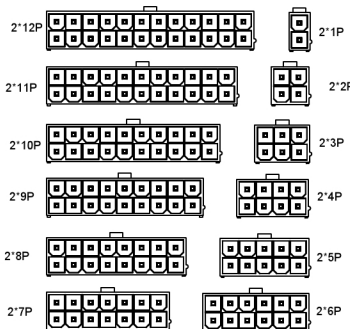

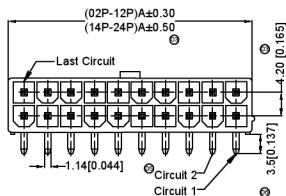
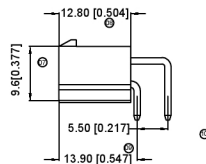
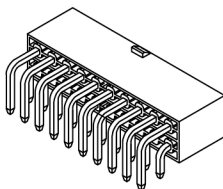


XKB

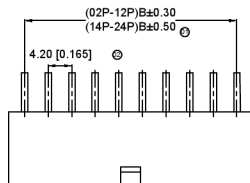

## Specifications:

规格: XKB  
**Voltage rating:**600V AC/DC  
**额定电压:** 600V AC/DC  
**Current rating:**9A AC/DC  
**额定电流:** 9A AC/DC  
**Withstanding voltage:**1500V AC/minute  
**耐受电压:** 1500V AC/分钟  
**Temperature range:**-25℃+85℃  
**温度范围:** -25℃+85℃  
**Insulation resistance:**≥1000MΩ  
**绝缘电阻:** ≥1000MΩ  
**Contact resistance:**≤10mΩ  
**接触电阻:** ≤10mΩ  
**After environmental test:**≤20mΩ  
**环境测试后:** ≤20mΩ

X9357WR X-2\*XX X-XX XX XX  
 ①②③④⑤⑥⑦⑧⑨⑩⑪⑫⑬⑭⑮⑯⑰⑱⑲

- 01 Series No  
 02 Category W-wafer  
 03 Welding Board Angle R-90  
 04 Welding Way: Blank-DIP  
 05 Row No. -Pin No. 2\*xx-Double  
 06 Plug the Pin&Special NO. F-HF  
 07 Material:  
 NG-PA66 94V-0;N2-PA66 94V-7  
 LP-LCP94V-0 BT-PA6T94V-0-9T-PA9T94V-0  
 08 Planting Category:  
 V.All Gold-Plated\*01-Gold Flash;  
 SN-Bright tin plating 70u"  
 09 Color:Blank-Natural Color BK-Black

Poles	Dimensions(mm)		Poles	Dimensions(mm)	
	A	B		A	B
2*01	5.60	—	2*07	30.80	25.20
2*02	9.80	4.20	2*08	35.00	29.40
2*03	14.00	8.40	2*09	39.20	33.60
2*04	18.20	12.60	2*10	43.40	37.80
2*05	22.40	16.80	2*11	47.60	42.00
2*06	26.60	21.00	2*12	51.80	46.20

X9357WR-2*XXX-N0V01XX	Nylon 66 UL 94V-0	Brass	Gold-Flash	X9357H	1,000P/CS
X9357WR-2*XXX-NGSNXX	Nylon66 UL94V-0	Brass	Tin-Plated		
X9357WR-2*XXX-N2V01XX	Nylon66 UL 94V-2	Brass	Gold-Flash		
X9357WR-2*XXX-N2SNXX	Nylon66 UL 94V-2	Brass	Tin-Plated		
PART NO	Material	Material(Pin)	Finish(Pin)	Suitable XKB	Qty/Bag

广东星坤科技股份有限公司

生 日期

文件工程章

REVISIONS

www.helxkb.com

XKB	ANGLAR	±5°
	L ≤ 4	±0.2
	4 < L ≤ 16	±0.3
	16 < L ≤ 63	±0.4
	L > 63	±0.5

UNSPECIFIED TOLERANCES

DSND	DATE	SCALE: N/A	MODEL TYPE: X9357WR-2*XX-XXXX
DWNN	DATE	VIEW:	PART NO.:
CHKD	DATE	UNIT: mm/in	4.2 mm Crimp Style Connectors
APPD	DATE	SIZE: A4	DWG NO.:
XKB INDUSTRIAL PRECISION CO., LIMITED			WEIGHT 1.0g
			SHEET 1/1
			REVISION A0