

NOTES1:

UL Standard

1. Rated voltage/current : 300V / 60A
2. Torque value : M4 , 10.53Lb.in
3. Wire range : 20~6AWG

IEC Standard




1. Rated voltage/current : 1000V/65A
2. Torque value : M4 , 1.2N.m
3. Wire range : 2.5~16mm²

NOTES2:

1. Dimension shall be interpreted per ASME Y14.5-2009
2. Pitch : 10.16mm, Poles : N=01~12P
3. Stripping length : 10~11mm
4. Withstanding voltage : AC3500V/1Min
5. Operating temperature: -40°C~+105°C
6. Undimensioned tolerances:

Pitch range in mm	Nominal dimension range in mm		-	~	D				
	Over	TO				Over	TO	Over	TO
6	10	TO	30	60	100	150	0.1/10		
10	24	TO	30	60	100	150	<		
±0.15±0.20		±0.30±0.50		±0.50±0.70		±1.00±1.30		±2°	

7. RoHS Compliance

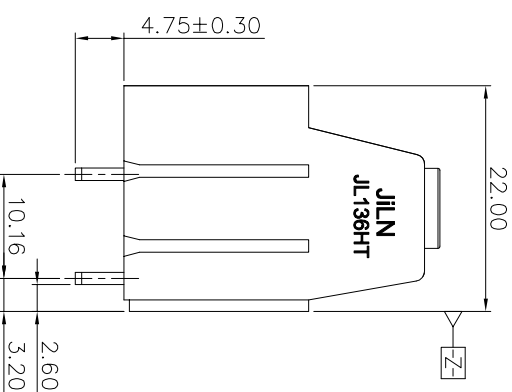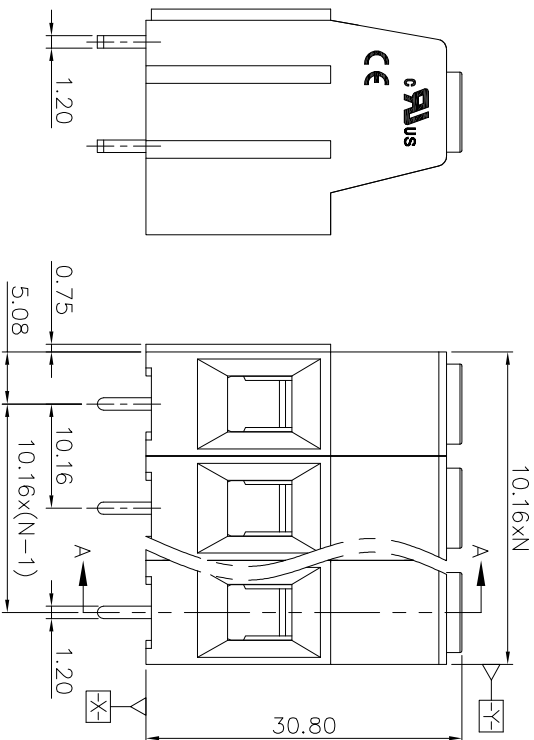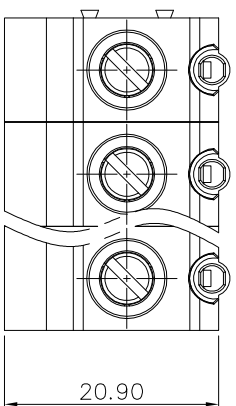


Ordering Information

JL136HT-1016 XX G 0 1

Pitch 1016=1016PH
 No.o.f pins 1P~12P
 Housing Color B=Black, G=Green, U=Blue, R=Red, W=White, Y=Yellow, D=Orange, E=Grey
 Packing 0=Pe bag, T=Tube, A=Tray

REVISION RECORD				
REV	ECN	DESCRIPTION	DRFT	DATE
A0		NEW		21.06.23

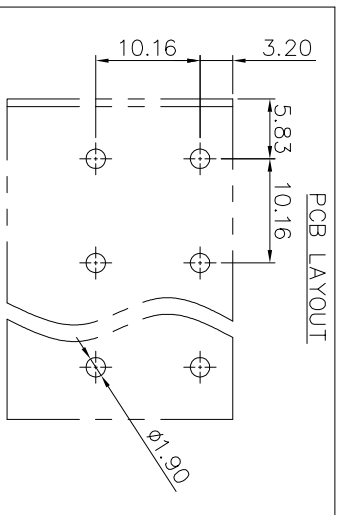

DRAW	SHUANGPING ZHENG		SCALE	FIT	PART NO.	TITLE:
	UNIT	mm	SIZE	A4		
CHECK	LICHAD LIU		SHEET	1/1	JL136HT-1016XXG01	JL136HT-10.16-XXP螺钉式绿色/一字螺丝
APPROVE	YONGLIANG GAO		PRD J			

JILIN 东莞市锦凌电子有限公司
 DONGGUAN JINLING ELECTRONIC CO., LTD