

SPECIFICATIONS

Rated(额定参数): 300V,8A  
 Dielectric strength(抗电强度): AC1500V/1 Minute  
 Insulation Resistance(绝缘电阻):1000MΩ Min  
 Contact Resistance(接触电阻):20mΩ Max  
 Wire Range(线径):28~16AWG  
 Strip length(剥线长度):8-9mm  
 Temp. range(操作温度): -40℃~+105℃  
 MAX Soldering(瞬时温度):+250℃,5s




Housing Material(塑件): PA66 (UL94 V-0)  
 Contact(端子): Phosphor Bronze, Tin plating(磷铜镀锡)

PITCH RANGE		NOMINAL DIMENSION RANGE					
IN MM		IN MM		IN MM		IN MM	
OVER	TO	OVER	TO	OVER	TO	OVER	TO
6	10	10	24	30	60	100	150
±0.10	±0.15	±0.25	±0.30	±0.30	±0.50	±0.70	±1.00

# Ordering Information

**JL15EDGKN - 350 XX G X 1**

Pitch  
350=3.5PH  
 No.of pins  
2P,3P,4P~24P  
 Housing Color  
B=Black  
G=Green  
U=Blue  
R=Red  
W=White  
Y=Yellow  
O=Orange  
F=Grey  
 Packing  
O=Pe bog  
A=Troy

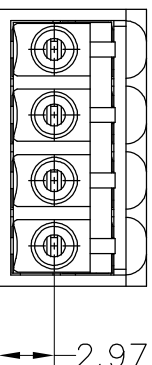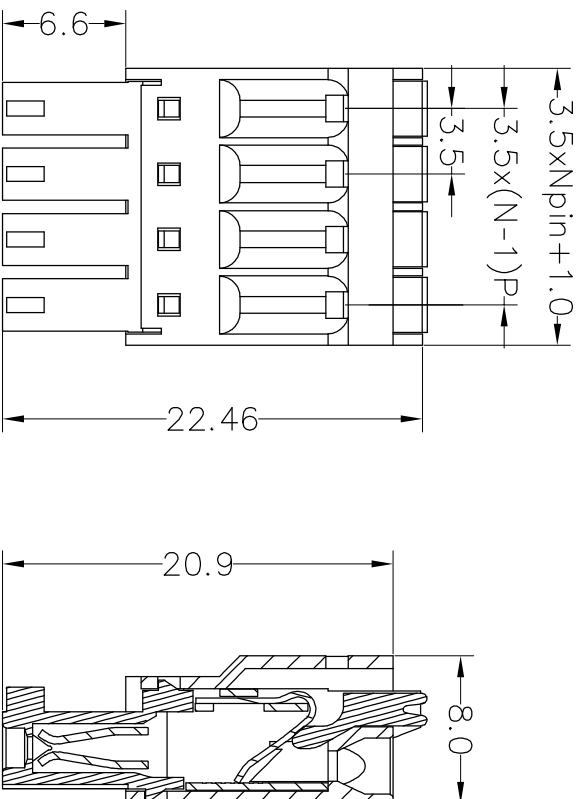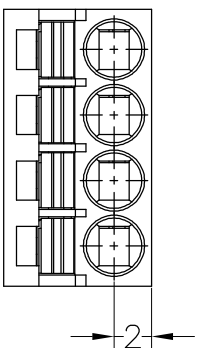

A		B		C		D		E		F		G	
REV	DATE	MODIFICATION	DESCRIPTION	CHANGE	DIM	TOL	APPROVE	SCALE	FIT	PART NO.	TITLE:	JL15EDGKN-350XXGX1 3.5mm Pitch Female Pluggable Terminal Blocks	
1	2020.05.22	NEW DRAWING			Angle	±3°	APPROVE	UNIT	mm	JLN®	东莞市锦凌电子有限公司	DONGGUAN JINLING ELECTRONIC CO.,LTD	
A0	2021.03.12	更改尺寸	LICHAO LIU		<del>X.XX</del>	±0.20	CHECK	SIZE	A4				
					X.XX	±0.30	DRAW	yiyusheng	20.05.22				
					OPERATION								