

SURGiNG

紹 鑫 實 業




Glass Discharge Tube


玻璃放电管

SSD41 Series

TypeSSD41 Series / 突波吸收器 Surge Absorber

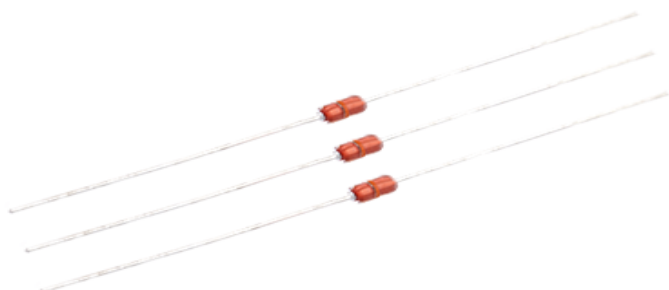

Dimensions(mm)尺寸

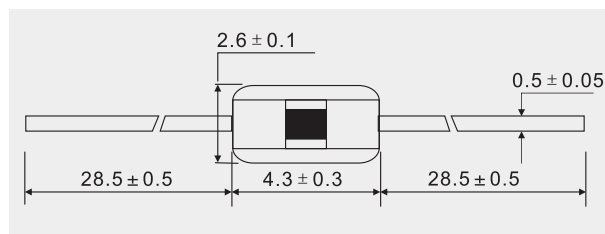

Features 特性

- Quick response
- Low capacitance
- Small size
- Low price

Applications 應用

- R.G.B and Grid of TV Monitor
- TEL,FAX,MODEM
- Power supply
- AUTO audio Frequency .navigation system

Electrical Specifications 電氣特性

Catalog Number 料號	DC Spark-Over Voltage 標稱直流擊穿電壓 100V/s Vs(V)	Impulse Spark Over 衝擊擊穿電壓 1KV / μs Vis(V) Max.	Nom Impulse Discharge Current 耐衝擊電流 8x20 μs kV	Nom Impulse Discharge Current 耐衝擊電流 8x20 μs(A)	Insulation Resistance 絕緣電阻		Capacitance 電容值 C 1kHz<6V pF Maz.
					Min. MΩ	DC V	
SSD41-141N	140V ± 30%	500	1.0	0.5	100	100	1.0
SSD41-201M	200V ± 20%	600	1.0	0.5	100	100	1.0
SSD41-301M	300V ± 20%	900	1.0	0.5	100	100	1.0
SSD41-401M	400V ± 20%	1000	1.0	0.5	100	250	1.0
SSD41-501M	500V ± 20%		1.0	0.5	100	250	1.0
SSD41-601M	600V ± 20%		1.0	0.5	100	250	1.0
SSD41-102M	1000V ± 20%		1.0	0.5	100	250	1.0

Materials 材料

Ceramic: Si Oxide
Metallization of Glass body
End termination : Dumet wire
End termination overcoat : Tin

Operation Temperature 工作溫度

-40°C to 125°C

Packaging 包裝

On Taping : SSD41 series-2000pcs Per Reel
SSD41 series-20000pcs outer box