

环保物料

TEL: 0769-82001899

SPECIFICATIONS

- 1.Voltage rating: 125V AC, DC
- 2.Current rating: 1A, AC, DC
- 3.Withstanding Voltage: 250V AC/minute
- 4.Insulation resistance:100M min
- 5.Temperature range: -25 °C-+85 °C
- 6.Contact resistance: 20m max

HOUSING

Housing Material:Nylon66 UL94V-0(2)

Accepts :T1258 terminal

Mates with: M1258 series header



Poles : 02-30P

Part No.: P1258-xxP


Pin位数

Dimensional & Ordering Information:

cir-cuits	Part No.	Dimension mm			BAG/pcs
		A	B	C	
02		1.25	2.72	5.72	1000
03		2.50	3.97	6.97	1000
04		3.75	5.22	8.22	1000
05		5.00	6.47	9.47	1000
06		6.25	7.72	10.72	1000
07		7.50	8.97	11.97	1000
08		8.75	10.22	13.22	1000
09		10.00	11.47	14.47	1000
10		11.25	12.72	15.72	1000
11		12.50	13.97	16.97	1000
12		13.75	15.22	18.22	1000
14		16.25	17.72	20.72	1000
15		17.50	18.97	21.97	1000
20		23.75	25.22	28.22	1000
30		36.25	37.72	40.72	1000

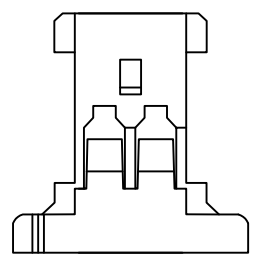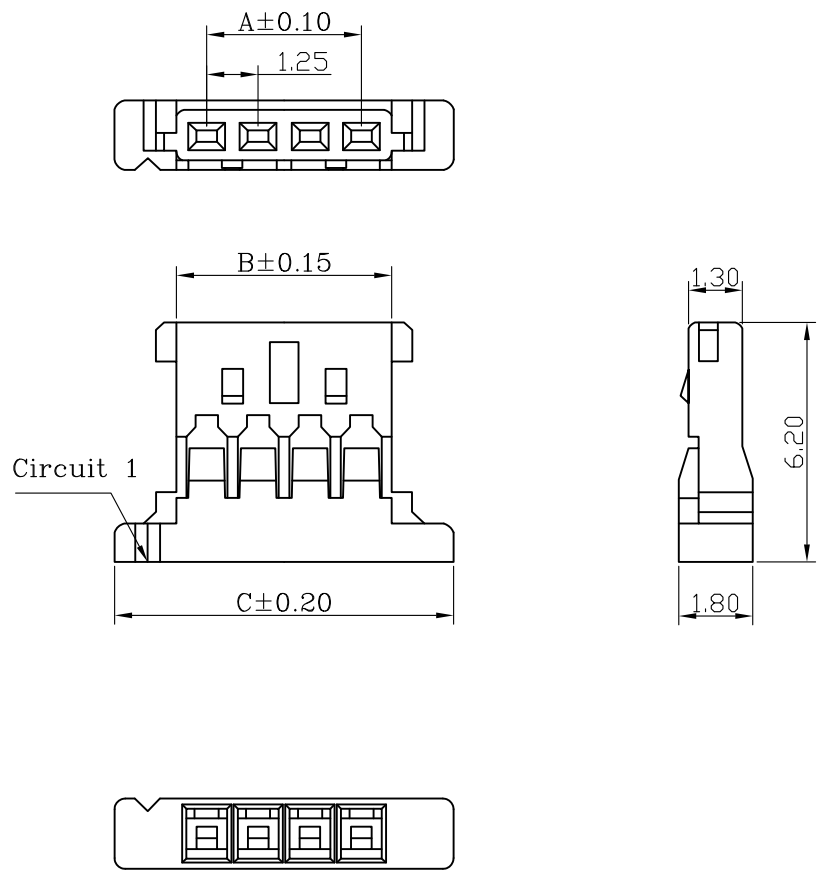

2P

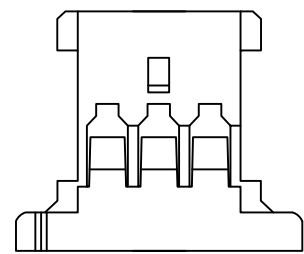

3P

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan
				X.	±0.30	X°	±5°
				.X	±0.20	.X°	±2°
				.XX	±0.08	.XX°	±1°
				.XXX	±0.03	.XXX°	±0.5°
AO	MODIFICATION	DRAW	DATE			VIEW	⊕

XFCN 兴飞连接器有限公司
XFCN CONNECTORS CO.,LTD.

PRODUCT NAME 1.25mm Crimp Style Connectors
PART. NO. P1258-xxP

SHEET	1/1
DATE	2020. 04. 12
UNITS	mm
SCALE	1:1
DWG NO.	009