


环保物料

TEL:0769-82001899

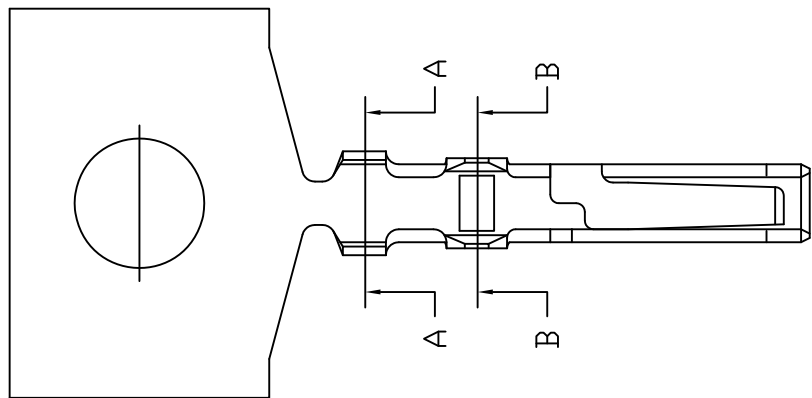

SPECIFICATIONS

- 1.Voltage rating: 125V AC, DC
- 2.Current rating: 1A, AC, DC
- 3.Withstanding Voltage: 250V AC/minute
- 4.Insulation resistance:100M min
- 5.Temperature range: -25 °C-+85 °C
- 6.Contact resistance: 20m max

TERMINAL

Material:Phosphor Bronze

Finish: Plated Tin or Plated Gold



Applicable wire: AWG#28-#32

Insulation O.D.:1.2-1.05mm(Max)


Used in :P1258 SERIES HOUSING

Qty/Reel: 15000PCS

Part No.: T1258-00

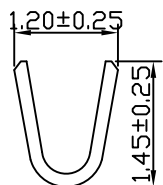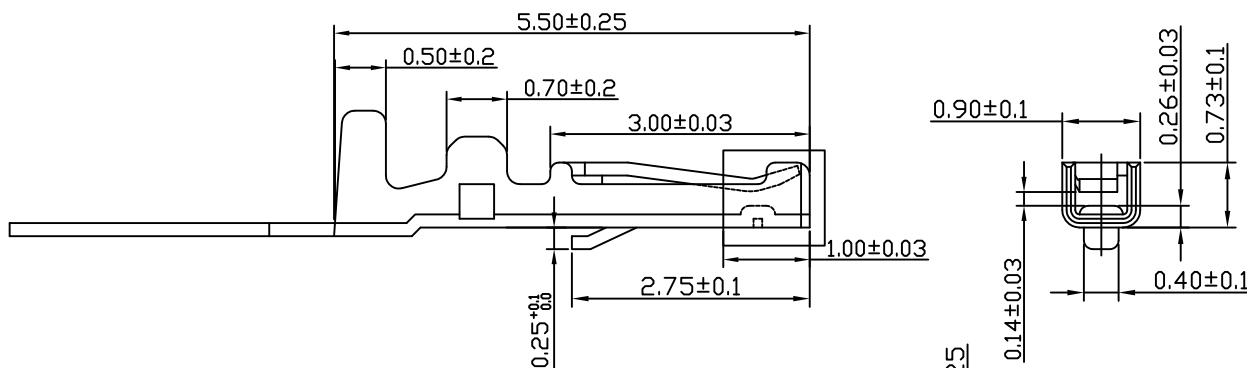

SEC:A-A

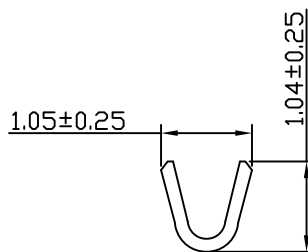

SEC:B-B

				TOLERANCE UNLESS OTHERWISE	DRAWN	CK tan	<b>XFCN</b> 兴飞连接器有限公司 XFCN CONNECTORS CO.,LTD.	SHEET	1/1		
				X. ±0.30 X° ±5°	CHKD			DATE	2020.04.12		
				.X ±0.20 .X° ±2°	APPD			UNITS	mm		
				.XX ±0.08 .XX° ±1°	VIEW	⊕		SCALE	1:1		
AO	MODIFICATION	DRAW	DATE	.XXX ±0.03 .XXX° ±0.5°			PRODUCT NAME	1.25mm Crimp Style Connectors	DWG NO.	009	
1	2	3	4	5	6	7	PART. NO.	T1258PS-00	8	9	10