


Push Switches

Long Stroke Push Switches



ロングストロークプッシュスイッチ(SPST)

- Rating: 50mA, 16V DC
- Travel: by table
- Operating Life: 300,000 cycles

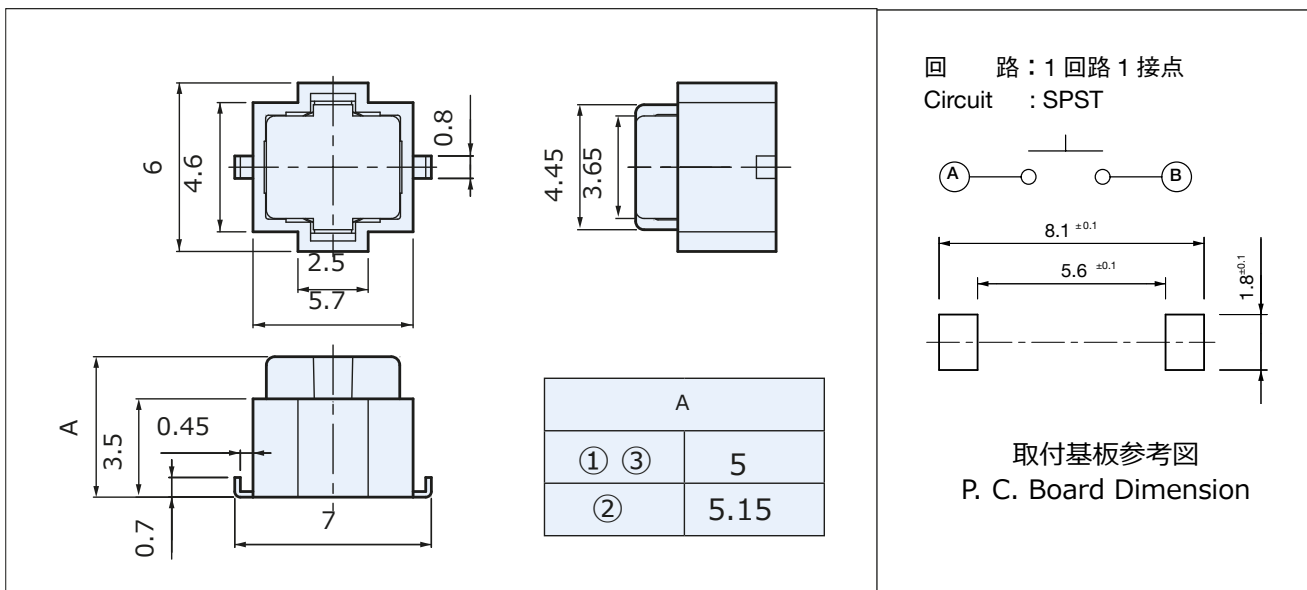

Part No. JPM1040-□□□□F					
Operating Force	On Travel	1.3mm		1.0mm	
	Full Travel	1.5mm		1.5mm※	
Height (A)	①		②		③
Country of origin	China	Japan	China	China	Japan
1.57±0.5N	1213	4211	2213	3213	6211
1.96±0.6N	0513	4511	2513	3513	6511
2.45±0.7N	0414	4413	2414	3414	6411
3.0±0.8N	0713	4713	2713	3713	6711
3.5±0.95N	0913	4911	2913	3913	6911
4.0±1.0N	1013	4011	2013	3013	6011

※ セット側に $1.35^{+0.1}$ mmの位置でストッパー機構を設けてください。