
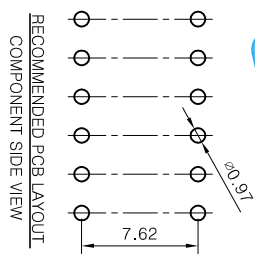
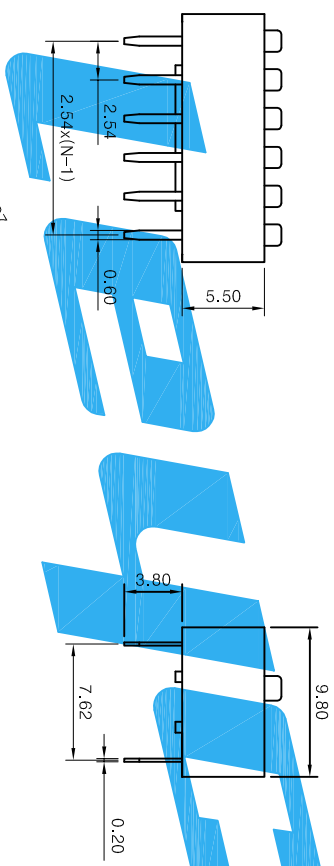
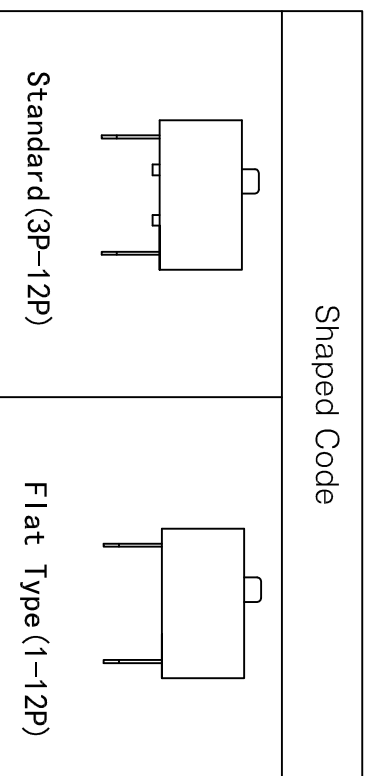


This document contains information confidential and proprietary to LEYCONN and shall not be reproduced or transferred to another document or disclosed to others or used for any purpose other than that for which it was obtained without the express written consent of LEYCONN.

RoHS

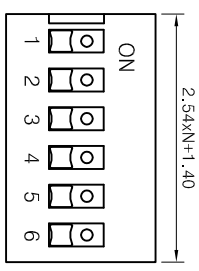

SPECIFICATIONS:
MECHANICAL:
 Operation force: 8N Max
 Operation temperature: -25°C to +70°C
 Storage temperature: -40°C to +85°C
ELECTRICAL:
 Electrical life: 2000 operations Cycles per switch 24 V/DC, 25mA
 Non-switching rating: 100mA 50V/DC
 Switching rating: 25mA 24V/DC
 Contact resistance: (a)50mΩ max. at initial (b)100mΩMin, after life test
 Insulation resistance: 100MΩMin, at 500V/DC
Circuit: single pole single throw
MATERIALS:
 Contact material: phosphor bronze
 Contact plating: gold over 50u" Ni
 Insulator material: Polyester(UL94V-0) Standard:PBT

Part Number:

460 NN 1 X X 1 X 1 0

Series Number:
 Number Contact:
 02-12
 Trial & Mounting Style:
 1-Straight DIP Type
 Pitch: (Unit:mm)
 1-2.54
 Packaging Options:
 1-Tube Packaging
 Shaped Code:
 0-Standard 1-Flat Type
 Contact Plated:
 1-Gold flash
 Insulator:
 1-Red 2-Blue

E		Units	mm	Scale	2:1	Drawing By	Date			LEYCONN ELECTRONICS CO.,LTD. 深圳市联益康电子有限公司 TEL: +86(755)26078616 FAX: 26070522	
D		Tolerance Unless		Otherwise Specified		YP-Liang	2019/03/15	Http://www.leyconn.com		1 of 1	
C		X ~ ±0.30		.XX ~ ±0.25		Nick-Yin	2019/03/15	Third Angle Projection		Title Switch Straight DIP Type H5.50	
B		RELEASED		15/03/19		Approval By	Date	Part No.		460NN1XX1X10	
A		DESCRIPTION:		Date		Kirby-Xiao	2019/03/15	Sheet		REV A	
1		2		3		4		5		6	
7		8									