


**◆ Features**

- 1、High-current SMD inductor.
- 2、Low-profile design.
- 3、High output processing capacity: Minimal copper loss
- 4、High saturation current and low DC resistance.
- 5、High operating frequency

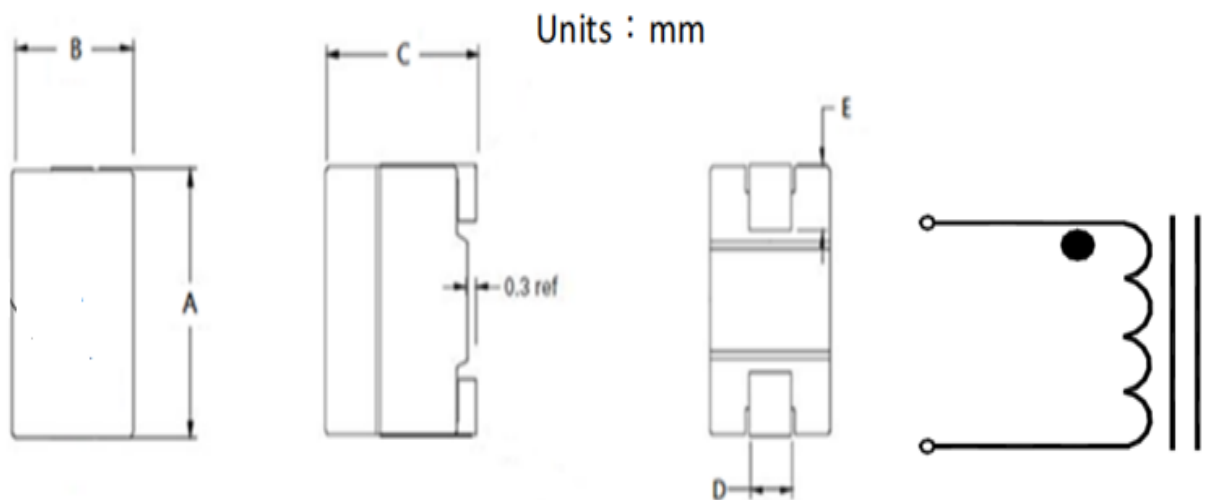

A	9.60	Max
B	6.40	Max
C	8.00	Max
D	2.14	REF
E	2.30	REF

**◆ Specification**

Part Number	Inductance @100KHz,1 V (μH)	DC Resistance	Saturation Current(A)	Heat Rating Current (A)
		±30% (Ω) DCR	Isat	Irms
SLA9060 Series				
SLA9060SR15MTT	0.15±20%	0.25	72	65
SLA9060SR22MTT	0.22±20%	0.29	51	44
SLA9060SR30MTT	0.30±20%	0.31	43	32.5

**◆ Standard Packing Quantity: 500 pcs/reel**