


- IEC60950 Compatible
- RoHS Compliance Product
- Surface Mount Device Providing Compact Footprint
- Operating temperature range:-40°C to +85°C




Electrical Specifications @25°C								
Part Number	Turns Ratio @20KHz, 1V	OCL @200KHz,0.1V	OCL @200KHz,0.1V (Ipk 2.6A/DC)	LK @100KHz,0.1V	DCR			HI-POT 1mA/3S
EFD-021SG	1,2-3,4:10,11,12-7,8,9:5-6	1,2-3,4	1,2-3,4	1,2-3,4(short other pins)	1,2-3,4	5-6	10,11,12-7,8,9	Pri/Aux TO Sec
	1:0.333:0.333±3%	42uH±10%	L _{2,6A} ≥90%(L _{0A})	1.0uH max	61mΩ max	195mΩ max	15mΩ max	1500V/AC

MECHANICAL

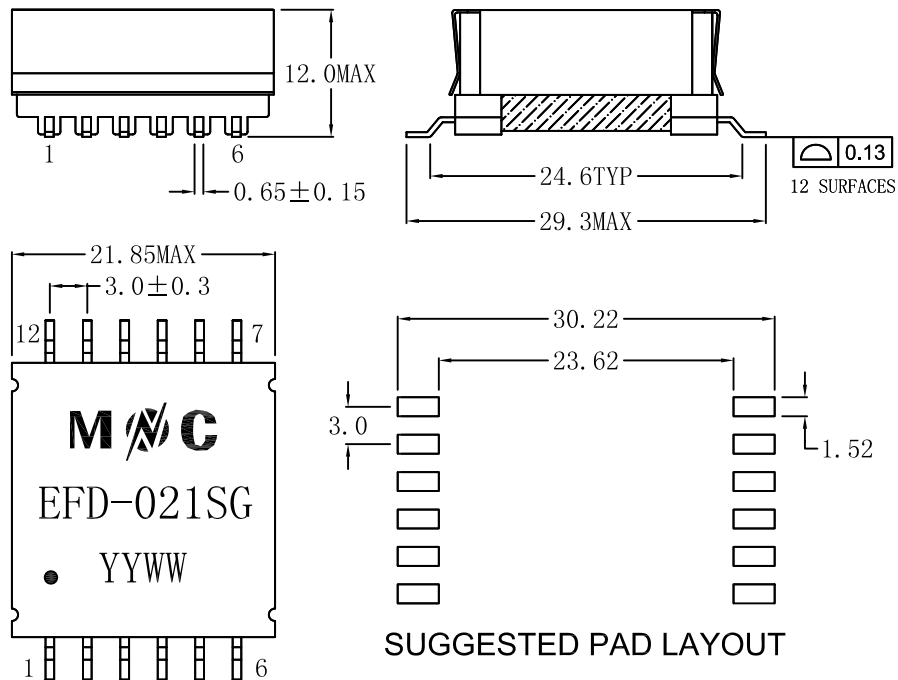

Unless otherwise specified all tolerances are:±0.25 in mm

SCHEMATICS

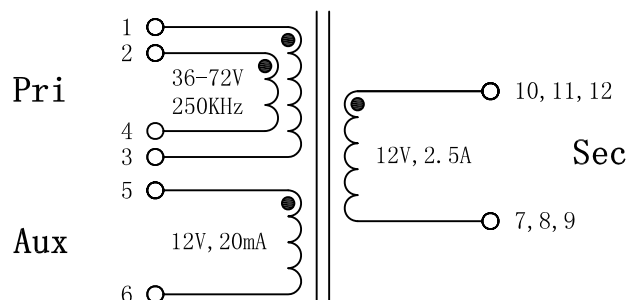

● Start Point