 

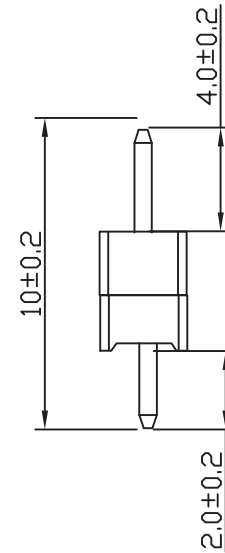
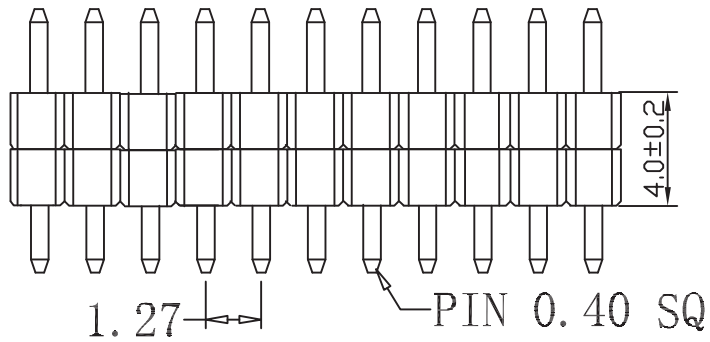


环保物料

TEL:0769-82001899

SPECIFICATIONS

- 1. Current Rate :1AMP
- 2. Operation Temperature:-40° C to+105° C
- 3. Contact Resistance :20m Ω Max.
- 4. Insulation Resistance:1000M Ω Min.
- 5. WithstandING Voltage :AC 500V
- 6. Insulator Material :Polyester(UL94V-0)
Standard:Nylon-PA6T
- 7. Contact Material :Brass
- 8. Contact plating :Au or Sn over 50U" Ni

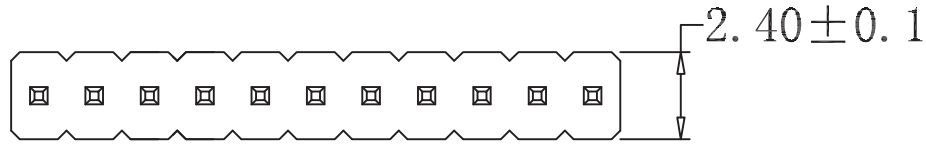

PCB LAYOUT

				TOLERANCE UNLESS OTHERWISE		DRAWN	CK tan	XFCN 兴飞连接器有限公司 XFCN CONNECTORS CO.,LTD.	SHEET	1/1	
				X.	±0.30	X°	±5°		CHKD	DATE	2020.04.12
				.X	±0.20	.X°	±2°		APPD	UNITS	mm
				.XX	±0.08	.XX°	±1°		VIEW	SCALE	1:1
AO				.XXX	±0.03	.XXX°	±0.5°	PRODUCT NAME	1.27mm Pin Header Connectors		
VER	MODIFICATION	DRAW	DATE					PART. NO.	PZ127V-21-xx-1000		