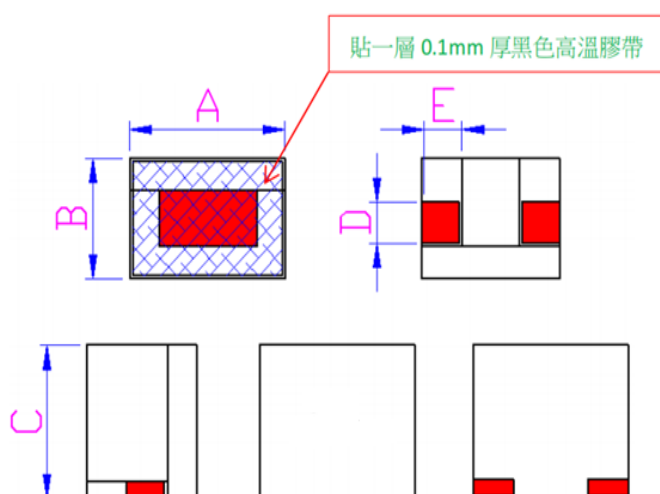


◆ Features

- 1、High-current SMD inductor.
- 2、Low-profile design.
- 3、High output processing capacity: Minimal copper loss
- 4、High saturation current and low DC resistance.
- 5、High operating frequency

◆ Dimensions


A	10.4	± 0.5
B	7.3	± 0.5
C	9.3	± 0.5
D	2.8	± 0.5
E	2.8	± 0.5

◆ Specification

Part Number	Inductance @100KHz, 1 V (μH)	DC Resistance	Saturation Current(A)	Heat Rating Current (A)
		±30% (Ω) DCR	Isat	Irms
SLA100709 Series				
SLA100709SR15LTT	0.15±15%	0.22	81	75
SLA100709SR22LTT	0.22±15%	0.24	66	60
SLA100709SR32LTT	0.32±15%	0.29	52	45
SLA100709SR47LTT	0.47±15%	0.44	26	21

◆ Standard Packing Quantity: 400 pcs/reel