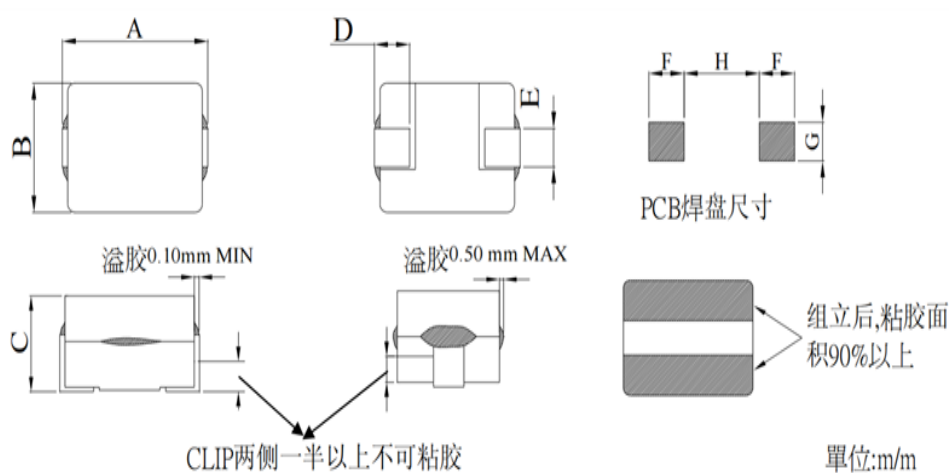


◆ Features

- 1、High-current SMD inductor.
- 2、Low-profile design.
- 3、High output processing capacity: Minimal copper loss
- 4、High saturation current and low DC resistance.
- 5、High operating frequency

◆ Dimensions


A	10.40	Max
B	8.0	Max
C	7.30	± 0.3
D	2.54	± 0.3
F	2.30	± 0.2
G	3.29	REF
H	2.79	REF
I	4.35	REF

◆ Specification

Part Number	Inductance @100KHz, 1 V (μH)	DC Resistance	Saturation Current(A)	Heat Rating Current (A)
		±30% (Ω) DCR	Isat	Irms
SLA1007 Series				
SLA1007SR17LTT	0.17±15%	0.29	67	60
SLA1007SR22KTT	0.22±10%	0.31	52	44

◆ Standard Packing Quantity: 500 pcs/reel