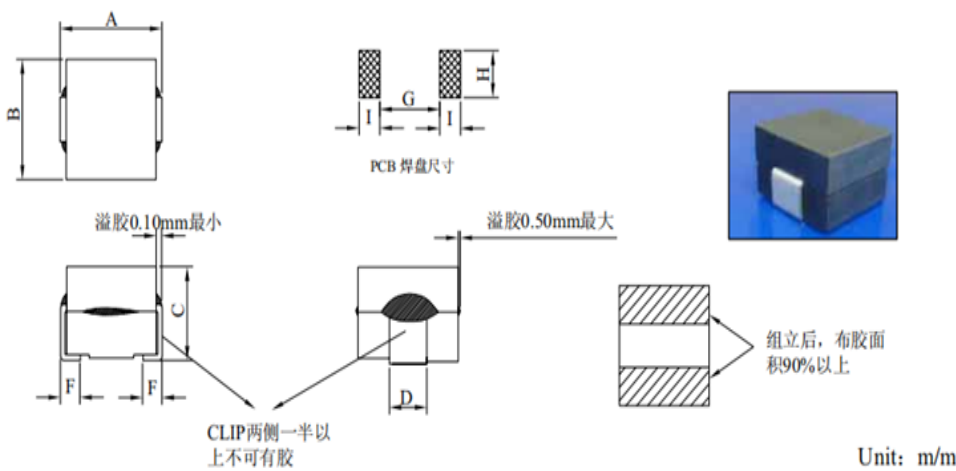


◆ Features

- 1、High-current SMD inductor.
- 2、Low-profile design.
- 3、High output processing capacity: Minimal copper loss
- 4、High saturation current and low DC resistance.
- 5、High operating frequency

◆ Dimensions


A	13.5	Max
B	13.0	Max
C	8.0	Max
D	5.0	± 0.3
F	2.5	± 0.2
G	7.11	REF
H	7.62	REF
I	3.2	REF

◆ Specification

Part Number	Inductance @100KHz, 1 V (μH)	DC Resistance	Saturation Current(A)	Heat Rating Current (A)
		±30% (Ω) DCR	Isat	Irms
SLA1408 Series				
SLA1408SR21MTT	0.21±20%	0.35	79	71
SLA1408SR26MTT	0.26±20%	0.37	66	60
SLA1408SR32MTT	0.32±20%	0.39	58	50
SLA1408SR44MTT	0.44±20%	0.42	43	35

◆ Standard Packing Quantity: 450 pcs/reel