

B5819W

B5819W Schottky Barrier Diode


General description

Flat Lead Plastic Package Schottky Barrier Diode


FEATURES

- For use in low voltage, high frequency inverters, free wheeling & polarity protection...
- Flat Lead SOD-123 Small Outline Plastic Package
- Surface Device Type Mounting
- RoHS Compliant
- Green EMC
- Matte Tin(Sn) Lead Finish
- Band Indicates Cathode
- Weight: approx. 0.01g

Green Product

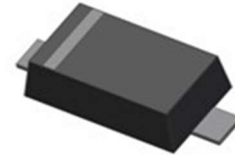

SOD-123 Flat Lead

 

Absolute Maximum Ratings TA = 25°C unless otherwise noted

Symbol	Parameter	Value	Units
P _D	Power Dissipation	500	mW
T _{STG}	Storage Temperature Range	-55 to +150	°C
T _J	Operating Junction Temperature	+150	°C
V _{RM}	Repetitive Peak Reverse Voltage	40	V
I _O	Average Rectified Output Current	1	A
I _{FSM}	Peak Forward Surge Current (t=8.3ms Single Half Sine-wave)	9	A
I _{FRM}	Repetitive Peak Forward Current	1.5	A



DEVICE MARKING CODE:

Device Type	Device Marking
B5819W	SL


Electrical Characteristics TA = 25°C unless otherwise noted

Symbol	Parameter	Test Condition	Limits			Unit
			Min	Typ	Max	
V _{BR}	Reverse Breakdown Voltage	I _R =1mA	40	--	-	Volts
I _R	Reverse Leakage Current	V _R =40V	--	--	1	mA
V _F	Forward Voltage	I _F =1A I _F =3A	--	--	0.60 0.90	Volts
C _d	Diode Capacitance	V _R =4V f=1MHz	--	--	120	pF

RATING AND CHARACTERISTIC CURVES

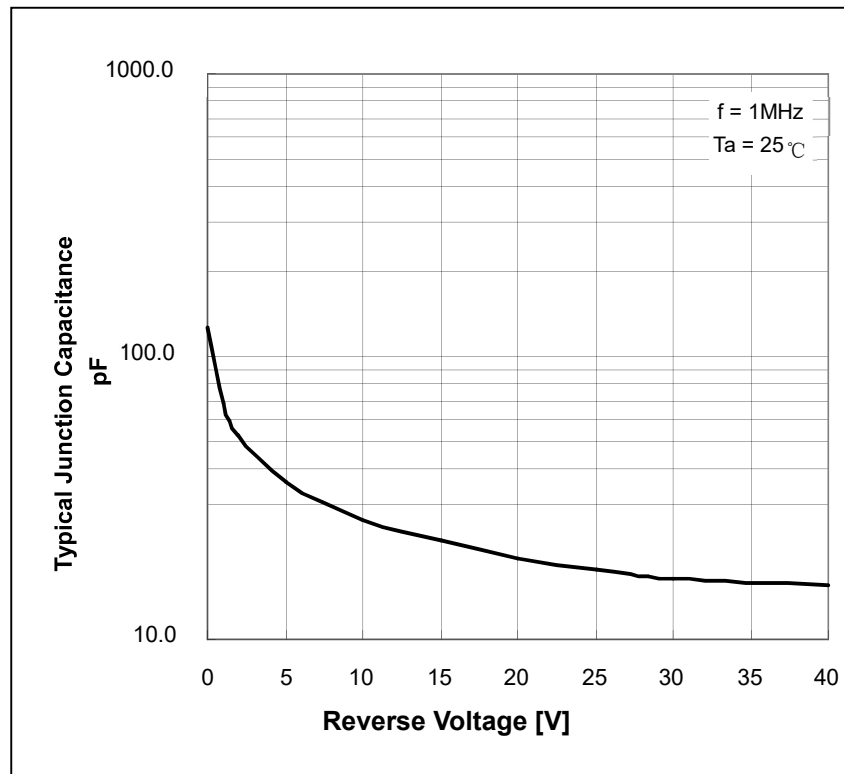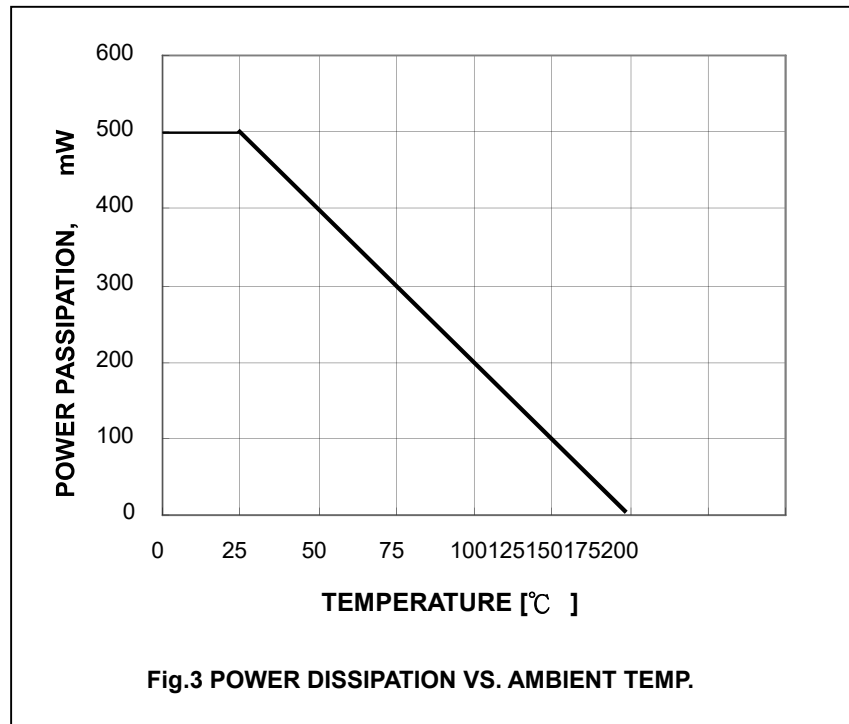

SOD-123 Package Outline

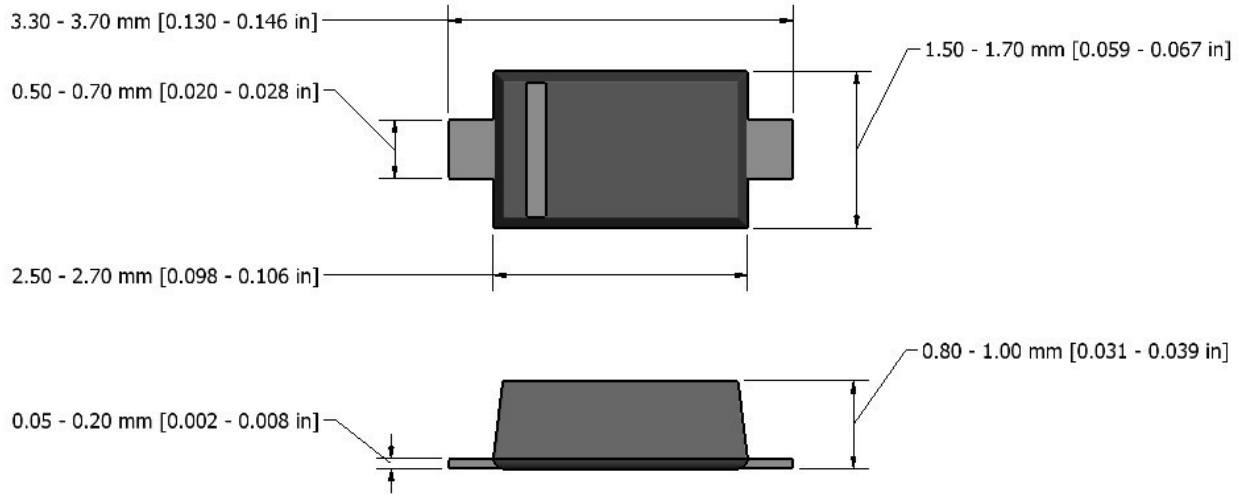

Note: Dimensions are exclusive of Burrs, Mold Flash & Tie Bar extrusions.

Important Notice and Disclaimer

DOESHARE has used reasonable care in preparing the information included in this document, but DOESHARE does not warrant that such information is error free. DOESHARE assumes no liability whatsoever for any damages incurred by you resulting from errors in or omissions from the information included herein.

DOESHARE no warranty, representation or guarantee regarding the documents, circuits and products specification, DOESHARE reservation rights to make changes for any documents, products, circuits and specifications at any time without notice.

Purchasers are solely responsible for the choice, selection and use of the DOESHARE products and services described herein, and DOESHARE assumes no liability whatsoever relating to the choice, selection or use of the products and services described herein.

No license, express or implied, by implication or otherwise under any intellectual property rights of DOESHARE.

Resale of DOESHARE products with provisions different from the statements and/or technical features set forth in this document shall immediately void any warranty granted by DOESHARE for the DOESHARE product or service described herein and shall not create or extend in any manner whatsoever, any liability of DOESHARE.