
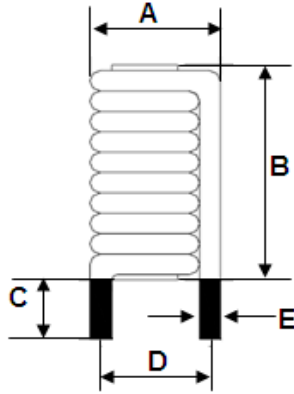
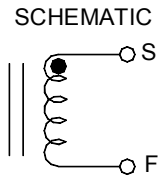


# 產品製作規格書

產品料號	<b>398-95095</b>	VER:0	產品名稱:	<b>IPB0622N/1.8-9.5-2R0M</b>				
圖面說明(單位:mm)			使用材料		注意事項			
  			A	R 6×22		(無鉛)		
			B	Ø1.8mm(1PEW)		原色		
			C					
			D					
			E					
			F					
			尺寸 (mm)					
			A	13.7 (Max)		E	Ø1.8±0.1	
			B	23(Max)		F		
			C	5.0±1.0		G		
D	11.0±0.5		H					
測試儀器		L (µH)	DCR (mΩ)	IDC A(Max)	測試條件			
TH2816B		2.0±20%	1.7±20%	20.0	10KHz,0.1V			
客戶編碼	產品料號	送樣編號	修改項目	修改參數				
	398-95095	A13-12027						
作業內容			包裝方式					
			A	50	PCS/袋	D		
			B	3	袋/盒	E		
			C	10	盒/箱	F		
修改記錄								
1.用R6×22的無鉛CORE.			時間	料號	修改內容			
2.用1PEWØ1.8mm的馬達線,繞9.5Ts			1					
或者用外調空芯線圈:Ø1.8×6.0×9.5 Ts-11.			2					
3.CORE與線圈點A.B膠固定.			3					
4.生產以無鉛制程制作.			4					
5.脫漆膜高度平CORE上0~2mm.			5					
6			6					
7			7					
8			8					
注意事項			9					
1.可使用同等功能儀器測試.			備 注					
2.感值,圈數都要求達到			A	1pcs產品的重量: 6.27g				
3.產品L值按100%全測, DCR值按10%抽測.			B					
4			C					
5			D					
核準: _____			審核: _____		製表: 張小萍			
					發文日期: 2014.06.27			