


REV. 0
DCO 141407

COIL: @ 25°C	
RESISTANCE	1560 OHMS ± 10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	14.2 VDC
MUST RELEASE	8.0 VDC MAX, 1.30 VDC MIN.

ENVIRONMENT:	
VIBRATION	10 CPS TO 3000 CPS @ 30 g's
SHOCK	75 g's 6 MS. DURATION
TEMPERATURE	-65 °C TO +125 °C

NOTES:	OPERATE TIME 2.5 MS MAX.
	RELEASE TIME 4.0 MS MAX.
	CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

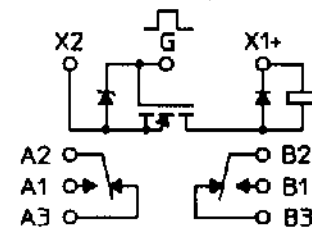

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 10/4/99 *CK* 10/4/99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I.
CUST. NO. COTS REV.

PRMGAT RELAY

PRMGAT-26XW