


KEMET Part Number: CK12BX101K
(C114K101K1X5CA)



LDD Mil X7R C11015, Ceramic, 100 pF, 10%, 100 VDC, BX

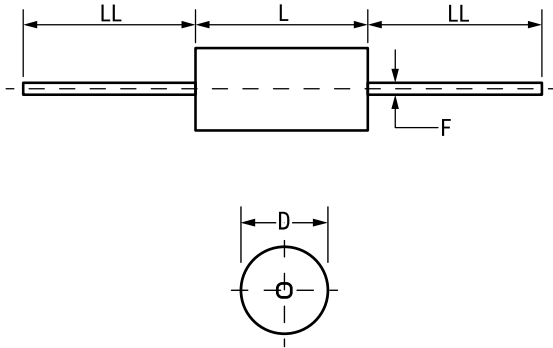

Dimensions	
D	2.29mm +/-0.25mm
L	4.06mm +/-0.25mm
LL	38.1mm MIN
F	0.51mm -0.08mm

Packaging Specifications	
Packaging:	Bulk, Bag
Packaging Quantity:	200

General Information	
Series:	LDD Mil X7R C11015
RoHS:	No
Prop 65:	WARNING: Cancer and reproductive harm - www.p65warnings.ca.gov .
REACH:	SVHC (Pb – CAS 7439-92-1)
SCIP Number:	f30e2214-6f19-489b-928a-4aa9281a81a7
Termination:	Lead (SnPb)
Testing and Reliability:	MIL-PRF-11015
Qualifications:	MIL-PRF-11015
AEC-Q200:	No

Specifications	
Capacitance:	100 pF
Capacitance Tolerance:	10%
Voltage DC:	100 VDC
Dielectric Withstanding Voltage:	250 VDC
Temperature Range:	-55/+125°C
Temperature Coefficient:	BX
Dissipation Factor:	2.5%

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

