

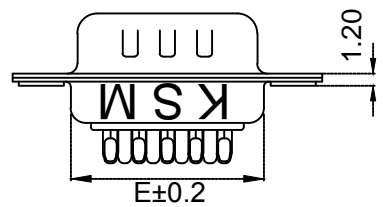


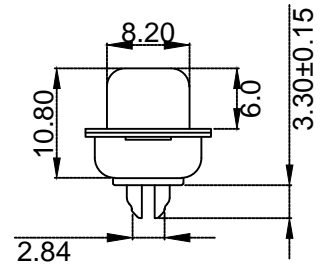

Material
 Insulator: Glass filled PBT, (UL 94V-0)
 Contact : Brass

Electrical Characteristics
 Current rating: 3AMP
 Dielectric Withstanding Voltage: AC 500V for 1 Minute.
 Insulator Resistance: 1000MΩ Min. AT DC 500V.
 Contact Resistance: 20mΩ Max.
 Operating Temperature: -45°C ~ +105°C

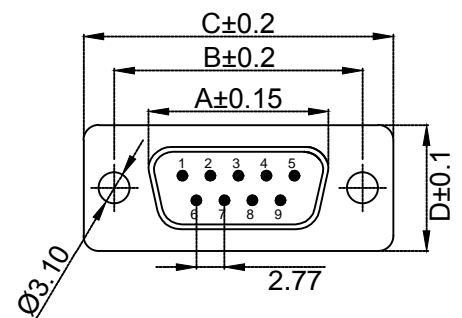

PIN	尺寸								D-sub solder type Male DB-9P/15P/25P/37P	上海洲日电子有限公司 Shanghai Zhouri Electronics CO.,LTD 上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD TEL:86-21-34975176/51571121						
	A±0.15	B±0.2	C±0.2	D±0.1	E±0.2											
DB-9P	17.90	25.00	30.80	12.50	19.20	X.	±0.3	±5°	20171018 A/0	ZR20171018-DB-61	TEL:86-21-34975176/51571121	1:1	mm	图幅	A4	
DB-15P	26.50	33.30	39.20	12.50	27.80	X.X	±0.2	±3°								
DB-25P	40.00	47.10	53.05	12.50	41.30	X.XX	±0.15									
DB-37P	56.50	63.50	69.44	12.50	57.50				201171018	物料编号						
									201171018							
									201171018							



: 1 1