


Nut Torque:5 ~ 14Nm
 Protection Grade:IP68,IK08
 Shell:Brass, Ni Plating
 Lamp Type:LED
 Lamp Color:Green
 Lamp Voltage:24V DC
 Forward current : 20mA MAX
 Lamp Life:50000H
 Operating Temperature: -20°C~80°C
 Relative Air Humidity:45%~85%
 Safety Approval:

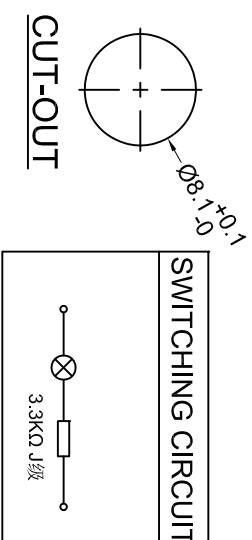

D-SWITCH
 东莞市德松电子有限公司
 D-SWITCH ELECTRONICS CO.,LTD

公差 TOLERANCES		.X±0.5 .XX±0.3		角度 ANGLE ±1°		单位 DIMENSION UNIT		mm.	
版本 VERSION	A0	比例尺 SCALE	1:1	日期 DATE	2022.03.18	品名 TITLE	图号 DRAWING NO		
核准 APPROVED BY		核对 CHECKED BY		绘图 DRAWN BY	孙成	PBM-8111-FS-G1-S24-B8W-6012 (L-100-1007#22-GG)	1030409		
版本 VER	变更说明 CHANGE DESCRIPTION	日期 DATE	ECON NO.						