

HSF RoHS **CE** **RAI** us **CE**

SPECIFICATIONS

Rated (额定参数): 300V, 8A
 Dielectric strength (抗电强度): AC1500V/1 Minute
 Insulation Resistance (绝缘电阻): 1000MΩ Min
 Contact Resistance (接触电阻): 20mΩ Max
 Screw Torque (扭矩): 0.2Nm (1.7Lb.in)
 Wire Range (线径): 1.6~2.8AWG
 Strip length (剥线长度): 6~7mm
 Temp. range (操作温度): -40°C~+105°C
 MAX Soldering (瞬时温度): +260°C, 5s

Housing Material (塑件): PA66 (UL94 V-0)
 Contact (端子): Phosphor Bronze, Tin plating (磷铜镀锡)
 Clamp (方块): Brass (黄铜), Ni plating (镀镍)
 Screw (螺丝): M2.0 Steel, Zinc plating (钢, 镀锌)

PITCH RANGE	NOMINAL DIMENSION RANGE					
	IN MM		IN MM		IN MM	
OVER	OVER	OVER	OVER	OVER	OVER	OVER
TO	TO	TO	TO	TO	TO	TO
6	10	10	30	60	100	150
±0.10	±0.15	±0.25	±0.30	±0.30	±0.50	±1.00

Ordering Information






JL15EDGKA - XXX XX G X 1

Pitch
 350=3.5PH
 381=3.81PH

No. of pins
 2P, 3P, 4P~24P

Housing Color
 B=Black
 G=Green
 U=Blue
 R=Red
 W=White
 Y=Yellow
 O=Orange
 E=Grey

Packing
 O=Pe bog
 T=Tube
 A=Troy

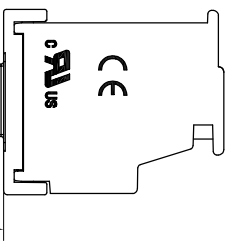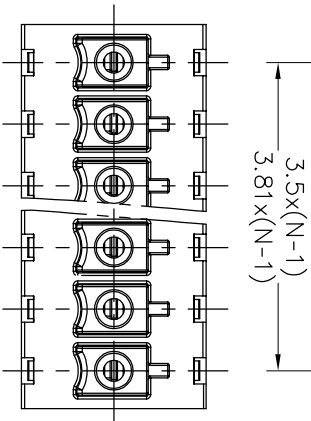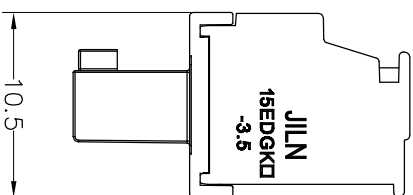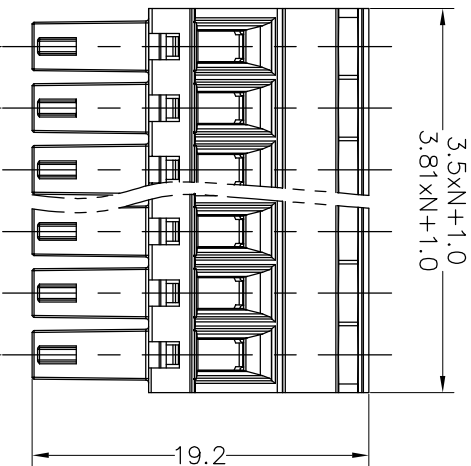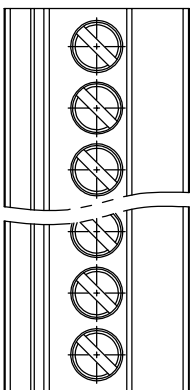

REV	DATE	MODIFICATION DESCRIPTION	CHANGE	OPERATION		DRAW	yiyusheng	20.03.03	SCALE	FIT	PART NO.	TITLE:
				ANGLE	TOL							
A0	2020.03.03	NEW DRAWING		X:XXX	±0.10	CHECK			A4	1/1	JL15EDGKA-XXXXXXG1	3.5/3.81 Pitch Female Pluggable Terminal Blocks
1												

JILIN 深圳市锦凌电子有限公司
 SHENZHEN JINLING ELECTRONIC CO.,LTD
 Tel: 86-755-2997-5806/5802 Fax: 86-755-2997-5992