
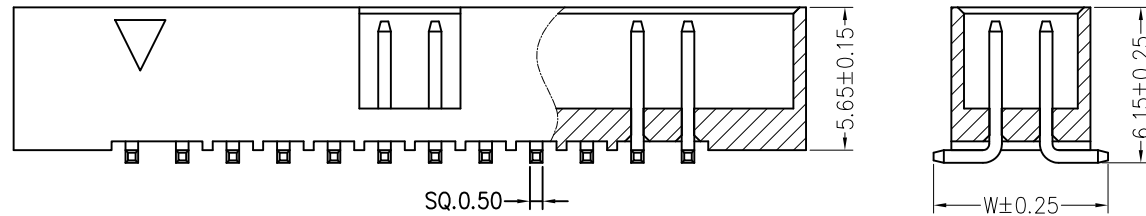
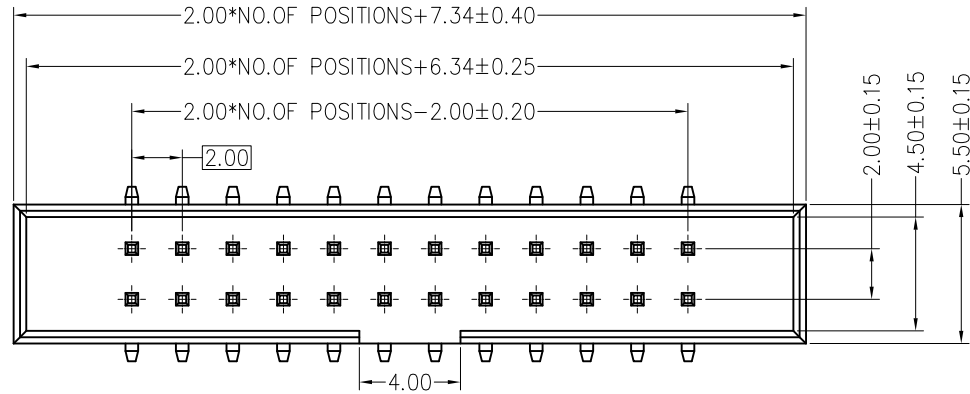


NOTES:  
 Voltage Rating:250V AC/DC  
 Current Rating:1.5A AC/DC  
 Dielectric Withstand Voltage:400V AC/minute  
 Contact Voltage:20M Max.  
 Insulation Voltage:800M Min  
 Operation temperature:-40 °C to +105 °C  
 Insulator Material:Polyester.UL94V-0  
 Contact Material:Brass  
 Contact Plating:AuorSn Plated on Nickel Overall

Recommended P.C.B Layout  
 P.C.B Board Tolerance±0.05

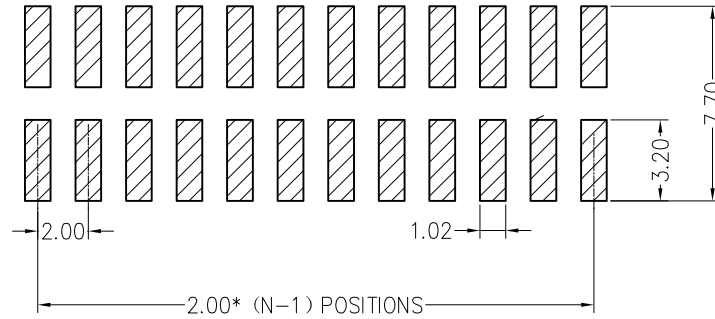

Dimension antitheses list

item	W	L
Standard	6.90	---
Alternate	---	---

TOLERANCE UNLESS OTHERWISE			DRAWN	CK tan
X.	±0.30	X° ±5°	CHKD	
.X	±0.20	.X° ±2°	APPD	
.XX	±0.08	.XX° ±1°		
.XXX	±0.03	.XXX° ±0.5°	VIEW	

**XFCN**兴飞连接器有限公司  
 CONNECTORS XFCN CONNECTORS CO., LTD.

PRODUCT NAME **2.00mm Box Header Connectors**

PART. NO. **BH200VS-2xXX**

SHEET	1/1
DATE	2010. 4. 12
UNITS	mm
SCALE	1:1
DWG. NO.	009

AO  
VER

MODIFICATION

DRAW

DATE