
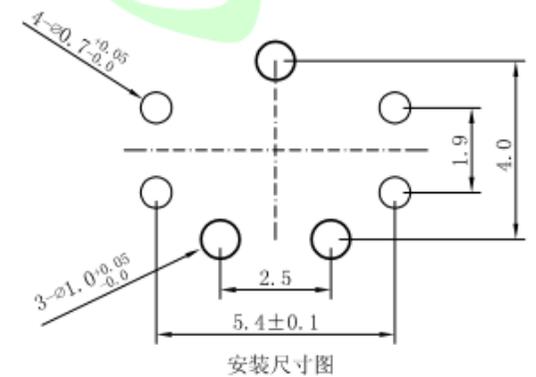


Technical Parameters

- 1. Rated current: DC 12V 50mA
- 2. Operating force: 30±10gf
- 3. Mechanical life: 100,000 times

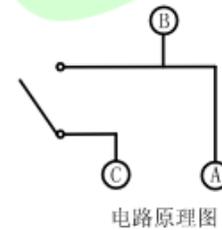

| | | | | | |
|-----|----------------|--------|-----|-----------------|-----------|
| Ⓔ | Terminal | | 2 | Phosphor bronze | Silvering |
| Ⓓ | Contact spring | | 1 | SUS | Silvering |
| Ⓒ | Button | | 1 | Nylon | Black |
| Ⓑ | Cover | | 1 | SUS | Black |
| Ⓐ | Base | | 1 | LCP | Black |
| NO. | Name | Number | Qty | Material | Remarks |

Dongguan Usakro Electronic Technology Co., Ltd.

| | | | |
|-------------|--------|-----------------|-------------------------|
| design | date | name | UK-D0436 |
| Review | date | name | 6.4*3.5 |
| Approved | date | Drawing number: | |
| modify | Review | Approved | Tolerance not specified |
| angle | ±2' | 10~30 | ±0.30 |
| | | 5~10 | ±0.20 |
| | | ~ 5 | ±0.10 |
| Proportion | 1:1 | unit | mm |
| gape number | | | |