



**Material**

Insulator: Glass filled PBT, (UL 94V-0)

Contact : Brass

**Electrical Characteristics**




Current rating: 3AMP

Dielectric Withstanding Voltage: AC 500V for 1 Minute.

Insulator Resistance: 1000MΩ Min. AT DC 500V.

Contact Resistance: 20mΩ Max.

Operating Temperature: -45 °C ~ +105 °C

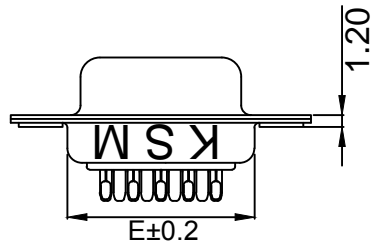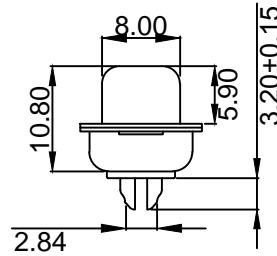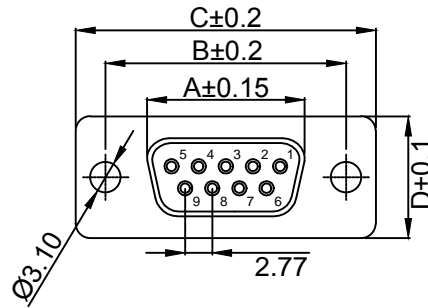

PIN	尺寸	A±0.15	B±0.2	C±0.2	D±0.1	E±0.2	D-sub solder type Female DB-9P/15P/25P/37P						
							X.	±0.3	±5°				
DB-9P		16.50	25.00	30.80	12.50	19.20	X.X	±0.2	±3°				
DB-15P		24.80	33.30	39.20	12.50	27.80	X.XX	±0.15					
DB-25P		38.55	47.10	53.10	12.50	41.20	201171018		20171018 A/0				
DB-37P		54.90	63.50	69.44	12.50	57.30	201171018		ZR20171018-DB-62				
							物料编号		201171018	1:1	mm	图幅	A4



: 1 1