


SURFACE MOUNT MLCCs 10 - 200 VDC

CASE SIZE			Voltage	AVAILABLE CAPACITANCE CODE																									
JDI	Inches	mm		0R5	XRX	100	120	150	180	220	270	330	390	470	560	680	820	101	121	151	181	221	271	331	391	471	561	681	821
R05 ■	0201	(0603) L .024 ±.001 W .012 ±.001 T .012 ±.001 EB .006 ±.002	25V	█																									
			16V	█											█														
			10V	█											█							█							
				█											█														
R07 ■	0402	(1005) L .040 ±.004 W .020 ±.004 T .025 Max. EB .008 ±.004	50V	█											█														
			25V	█											█														
			16V	█											█														
			10V	█											█														
R14 ■	0603	(1608) L .063 ±.008 W .032 ±.008 T .035 Max. EB .010±.005	200V	█											█														
			100V	█											█														
			50V	█											█														
			25V	█											█														
			16V	█											█														
R15 ■	0805	(2012) L .080 ±.010 W .050 ±.010 T .050 Max. EB .020±.010	200V	█											█														
			100V	█											█														
			50V	█											█														
			25V	█											█														
			16V	█											█														
R18 ■	1206	(3216) L .125 ±.010 W .062 ±.010 T .050 Max. EB .020 ±.010	200V	█											█														
			100V	█											█														
			50V	█											█														
			25V	█											█														
			16V	█											█														
S41 ■	1210	(3224) L .125 ±.010 W .095 ±.010 T .065 Max. EB .020 ±.010	200V	█											█														
			100V	█											█														
			50V	█											█														
			25V	█											█														
			16V	█											█														
S43 ■	1812	(4532) L .175 ±.010 W .125 ±.010 T .085 Max. EB .025 ±.015	200V	█											█														
			100V	█											█														
			50V	█											█														
			25V	█											█														
			16V	█											█														

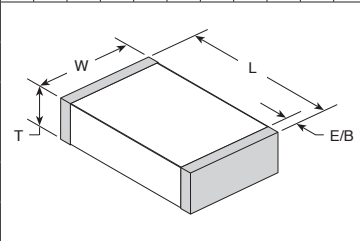

AVAILABLE CAPACITANCE CODE																								Voltage	CASE SIZE			
122	152	182	222	272	332	392	472	562	822	103	123	153	183	223	273	333	473	563	683	823	104	224	334			474		
																										NPO	25V	0201 R05
																										X7R	16V	
																										X5R	10V	
																											50V	0402 R07
																											25V	
																											16V	
																											10V	
																											200V	0603 R14
																											100V	
																											50V	
																											25V	
																											16V	
																											200V	0805 R15
																											100V	
																											50V	
																											25V	
																											16V	
																											200V	1206 R18
																											100V	
																											50V	
																											25V	
																											16V	
																											200V	1210 S41
																											100V	
																											50V	
																											25V	
																											16V	
																											200V	1812 S43
																											100V	
																											50V	
																											25V	
																											16V	

