

Operation: DIP/卧式 2.0 USB-A/M 连接器



LTEM NO.: USB-05 (Series)

(L10.0×W13.1×H6.3 2.0-USB-CONNECTORS)

沉板插装 DIP

側向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS



Technical parameter

 

PROJECT	LEVEL	A[better product]		B[average product]	
Electrical Properties	Contact Rating	1.0A, 24V DC			
	Initial Contact Resistance	50mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut		
Durable Performance	There No Load	6,000 Cycles	5,000 Cycles		
	Rated Load	5,000 Cycles	4,000 Cycles		
	Storage temp.	-35℃~+75℃(Operating Temp:)			
	Operating Force	IF:20N MAX. (EF:10.0N MIN.)			
	Heat Rrsistance	IR Reflow:235℃, 5sec. Manual :350℃, 3sec.			

Material declaration		
No.	NAME	Description
① A	胶芯	PBT 塑胶+30%LCP
② B	接触端子	磷铜 C5191 (镀金 1u" / 焊尾雾锡)
③ C	外壳	双光铁 [镀镍 50u" min]

PIN SIGNAL

Pin No.	Signal Name	Description
1	VCC	+5V
2	-DATA 0	Neagative Data Channel 0
3	+DATA 0	Positive Data Channel 0
4	GND	Ground

Unit:mm

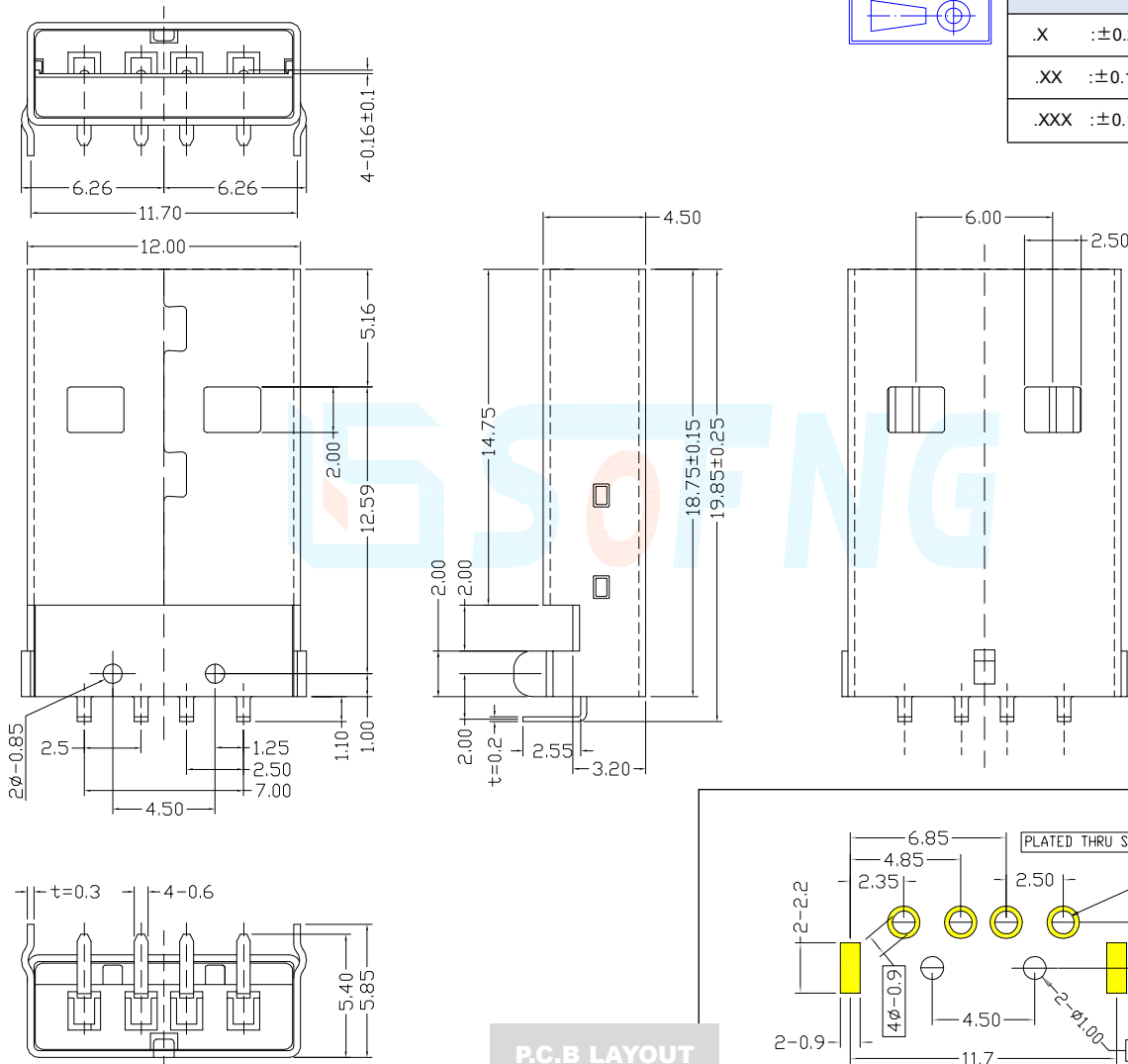

DECIMALS	ANGLES
.X :±0.25	X.° :±1.5°
.XX :±0.15	X.X° :±1.0°
.XXX :±0.10	.XXX° :±0.5°

P.C.B LAYOUT

