


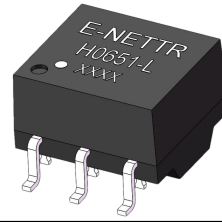

E-NETTR Single Port Transformer Module

P/N: H0651-L


- * Designed to meet RoHS requirement
- * Designed to meet IR 255°C peak Requirement.
- * Primary inductance 150μH min.
- * Operating temperature range: -40°C to +125°C



Electrical Specifications@25° C


Part Number	Turn Ratio ±2%	Insertion Loss (dB Max)	Return Loss (dB Min)	CMRR (dB Min)		100KHZ 0.1V		DCR Ω	Hi-Pot (Vrms MIN)
		4MHZ	4MHz	1-10MHz	10- 1000MHz	LX	LK		
H0651-L	1CT:1CT	-0.25	-20	-35	-20	150uH MIN	0.4uH MAX	0.85MAX	DC 4300V

Mechanical

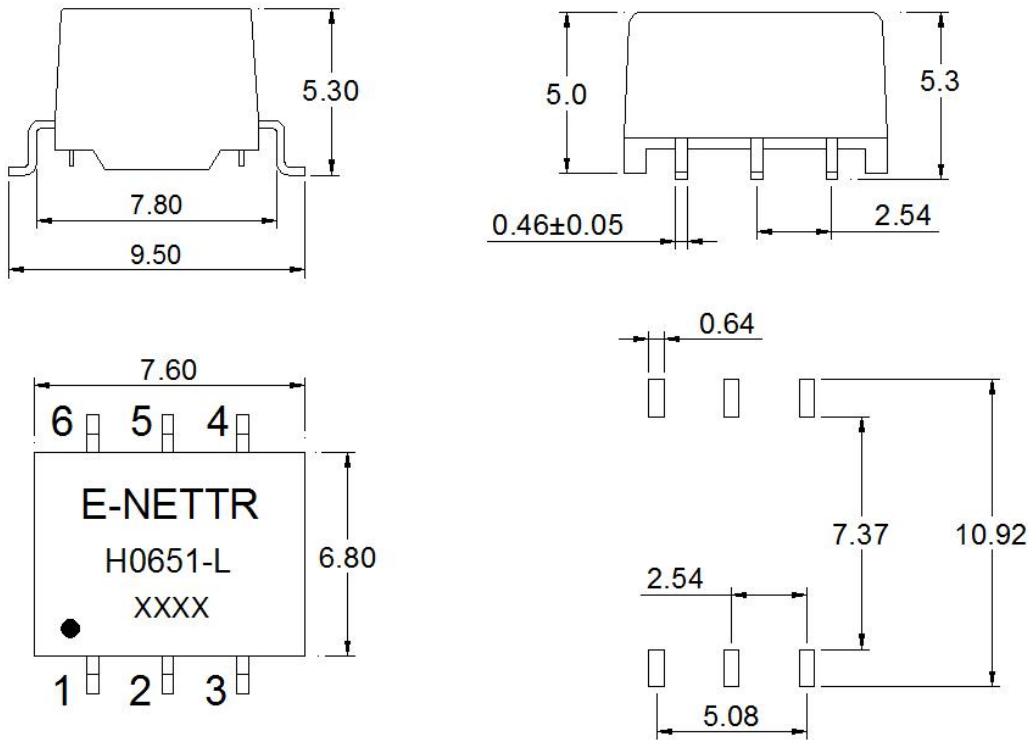

Unless otherwise specified tolerances: xx.xo ± 0.25mm
o.xx ± 0.05mm

Schematic

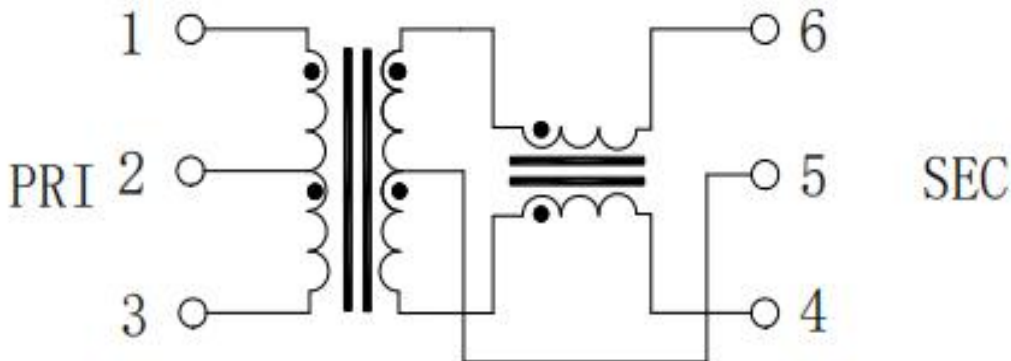

东莞市祥星电子有限公司

地址：东莞市石碣镇横滘科技中路第三工业区

TEL:0769-86384669

FAX:0769-81813600

Miss yang:13694998066

Http://www.e-nettr.com

Mr Li:15013501940

xxing.guang@163.com