


PARTS NUMBER SYSTEM

JAMICON®

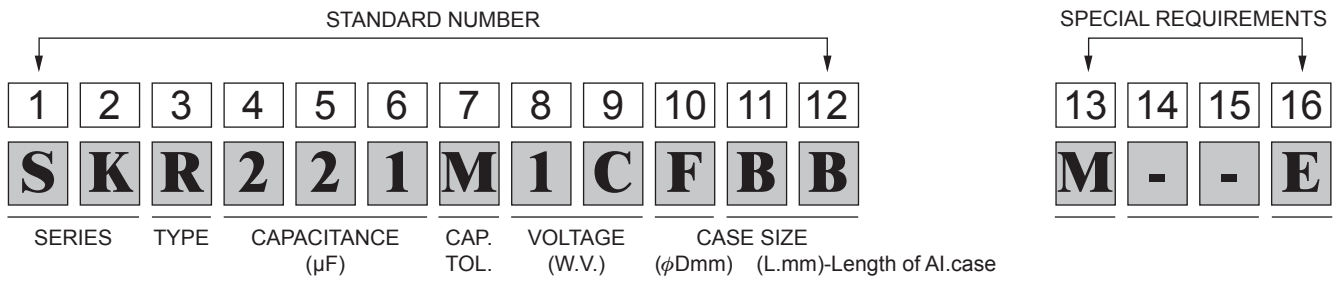

| Series | | | Code | Type | Description | CAP (μF) | Code | Tolerance (%) | Code | Voltage (W.V.) | Code | Diameter (φ) | Code | Length (L) | Code | Code | Description |
|--------|-----------|----|------|--------|---------------------|----------|------------|---------------|------|----------------|-----------|--------------|----------|------------|------|------|-----------------|
| PS | SS | UK | R | Radial | Bulk | 0.1 | OR1 | +10 | K | 2.5 | 0E | 3 | A | 11 | 11 | W | Without Sleeve |
| PT | SH | NC | | | | 0.22 | R22 | -10 | | 4 | 0G | 3.8 | S | 11.5 | BB | | Customer Assign |
| PH | SL | RV | P | Radial | Taping (Ammo Pack) | 0.33 | R33 | +15 | L | 6.3 | 0J | 4 | C | 12.5 | BC | 1~9 | Customer Assign |
| PC | NS | LP | | | | 0.47 | R47 | -15 | | 10 | 1A | 5 | D | 31.5 | DB | | |
| PF | SK | HP | C | Radial | Lead Cut | 1 | 010 | +20 | M | 13 | 1P | 6 | W | 35.5 | DF | a~ | Brand |
| PB | SM | LS | | | | 2.2 | 2R2 | -20 | | 16 | 1C | 6.3 | E | 100 | 1H | | |
| CS | TK | HS | F | Radial | Lead Forming Cut | 3.3 | 3R3 | +100 | P | 20 | 1D | 7 | Y | 110 | 1A | Code | Description |
| CA | TM | HM | | | | 4.7 | 4R7 | -0 | | 25 | 1E | 8 | F | 115 | 1K | | |
| CN | NK | LT | B | Radial | Lead Forming Only | 10 | 100 | +30 | Q | 35 | 1V | 10 | G | 120 | 1B | E | PET Sleeve |
| CR | LK | LL | | | | 22 | 220 | -10 | | 40 | 1G | 12 | H | 121 | 1M | | |
| CT | MZ | HT | Y | Radial | Lead Snap in | 33 | 330 | +20 | R | 50 | 1H | 12.5 | I | 130 | 1C | Code | Description |
| CE | TB | HV | | | | 47 | 470 | -0 | | 63 | 1J | 13 | J | 131 | 1P | | |
| CP | TP | HL | W | Lug | Snap in Terminal | 100 | 101 | +50 | T | 80 | 1K | 16 | K | 140 | 1D | Code | Description |
| CH | WL | HF | | | | 220 | 221 | -10 | | 100 | 2A | 18 | L | 144 | 1Q | | |
| CU | WJ | HX | G | Lug | G Type Terminal | 330 | 331 | +75 | U | 125 | 2B | 20 | M | 150 | 1E | Code | Description |
| CL | WG | KP | | | | 470 | 471 | -10 | | 160 | 2C | 22 | N | 155 | 1N | | |
| CF | TL | MP | V | Lug | V Type Terminal | 1000 | 102 | +20 | V | 180 | 2M | 25 | O | 157 | 1R | Code | Description |
| CK | TZ | GP | | | | 2200 | 222 | -10 | | 200 | 2D | 30 | P | 160 | 1F | | |
| CZ | TC | RP | S | Screw | Screw Terminal Type | 3300 | 332 | +20 | H | 250 | 2E | 35 | Q | 170 | 1G | Code | Description |
| CD | TH | XP | | | | 4700 | 472 | -5 | | 315 | 2F | 40 | R | 180 | 1I | | |
| CJ | TX | BP | M | Chip | Surface Mount Type | 10000 | 103 | +30 | F | 330 | 2U | 51 | V | 190 | 1J | Code | Description |
| CB | TJ | FP | | | | 22000 | 223 | -0 | | 350 | 2V | 64 | 1 | 196 | 1S | | |
| SV | TF | EP | | | | 33000 | 333 | +100 | W | 400 | 2G | 77 | 2 | 215 | 1L | Code | Description |
| ST | TA | | | | | 47000 | 473 | -10 | | 450 | 2W | 90 | 3 | 236 | 1T | | |
| NT | WB | | | | | | | | | 500 | 2H | | | | | | |