


PIN针规格

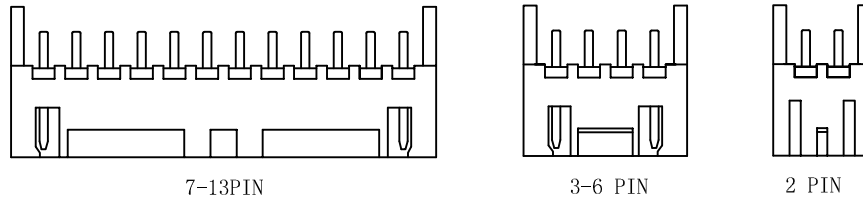

■ SPECIFICATIONS

- Voltage rating: 250V AC/DC
- Current rating: 3.0A, AC/DC
- Withstanding Voltage: 1000VAC/minute
- Insulation resistance: 1,000MΩ min
- Temperature range: -40°C to +105°C
- Contact resistance: 20mΩ max

■ WAFER

- Part No: CS-1001R-09B (LOCK)
- Poles: 2-13
- Material: PA66 A63 UL 94V-0, White
- Q'TY: 1,000 pcs/Tape&reel

| NO | PART NO | DIMENSION (mm) | | | |
|----|---------------------|----------------|-------|-------|------|
| | Top entry type | A | B | C | D |
| 2 | CS-1001R-02B (LOCK) | 7.50 | 5.90 | 2.50 | 0.85 |
| 3 | CS-1001R-03B (LOCK) | 10.00 | 8.40 | 5.00 | 2.1 |
| 4 | CS-1001R-04B (LOCK) | 12.50 | 10.90 | 7.50 | 4.3 |
| 5 | CS-1001R-05B (LOCK) | 15.00 | 13.40 | 10.00 | 6.9 |
| 6 | CS-1001R-06B (LOCK) | 17.50 | 15.90 | 12.50 | 9.4 |
| 7 | CS-1001R-07B (LOCK) | 20.00 | 18.40 | 15.00 | 2 |
| 8 | CS-1001R-08B (LOCK) | 22.50 | 20.90 | 17.50 | 2 |
| 9 | CS-1001R-09B (LOCK) | 25.00 | 23.40 | 20.00 | 2 |
| 10 | CS-1001R-10B (LOCK) | 27.50 | 25.90 | 22.50 | 2 |
| 11 | CS-1001R-11B (LOCK) | 30.00 | 28.40 | 25.00 | 2 |
| 12 | CS-1001R-12B (LOCK) | 32.50 | 30.90 | 27.50 | 2 |
| 13 | CS-1001R-13B (LOCK) | 35.00 | 33.40 | 30.00 | 2 |

ROHS2.0

本圖紙知識產權及版權由深圳市永丰盈电子有限公司所有,未經書面許可不准擅自傳閱、复制和修改。本公司保留法律追究的权利。

| | | | | | | | | | | | | | | |
|------|------------|----|---------------------|--------|-------|---|----|----|-----|--------------|------|------|--|--|
| 类别 | WAFER | 品名 | CS-1001R-09B (LOCK) | X. | ±0.50 | 材料 | | 单位 | mm | SHEET 1 OF 1 | | | | |
| 版本 | A/0 | 设计 | 李文畅 | X.X | ±0.40 | 颜色 | 本色 | 比例 | 1:1 | ▲ | 修改内容 | 修改日期 | | |
| 制定部门 | 工程部 | 绘制 | 李文畅 | X.XX | ±0.30 | 画法 | | 数量 | | ▲ | | | | |
| 工程图号 | CST-1001R | 审核 | 姚培柱 | X.XXX | ±0.20 | CST 深圳市永丰盈电子有限公司 ShenZhenYongFengYing ELECTRONICS CO.,LTD. | | | | | | ▲ | | |
| 制定日期 | 2018/11/30 | 核准 | 周中湖 | X.XXXX | ±0.10 | | | | | | | ▲ | | |

CST 深圳市永丰盈电子有限公司
ShenZhenYongFengYing ELECTRONICS CO.,LTD.

| | | |
|---|--|--|
| ▲ | | |
| ▲ | | |
| ▲ | | |
| ▲ | | |