
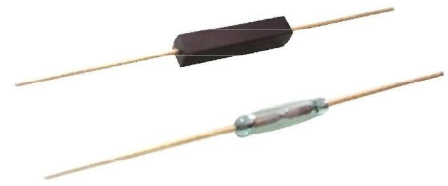


PCB/SMD Mount Reed Switch/Sensor

<b>Product Name</b>	Normally Open Reed Sensor	<b>Item No.</b>	FRS-11A41H / SZFAST-J
---------------------	---------------------------	-----------------	-----------------------

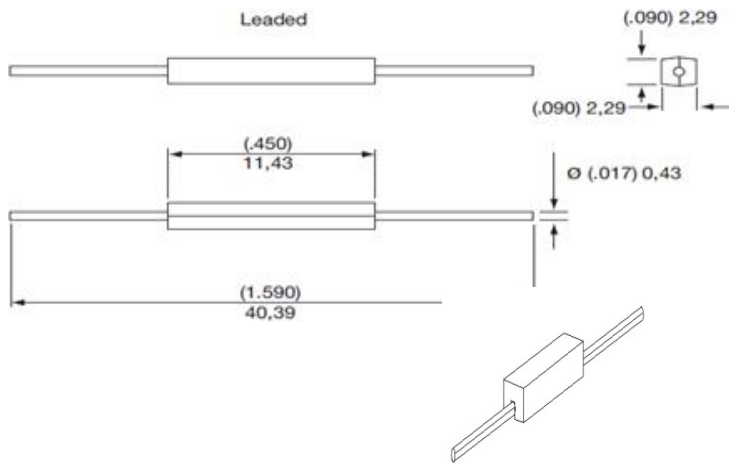

**Advantages:**

1. Easy installation, operate in magnetic field.
2. Passive switch, no need outer power
3. Cut through any non-iron materials.

Item Numbers	FRS-11A41H 📞	SZFAST-J-02 📞
Built-in reed switch	MKA10110	RI-02
Switch Form	Form A-SPST	Form A-SPST
Operate Range (AT)	8-40	9-15
Operate Time (ms)	0.35	0.30
Resonant Frequency (Hz)	5000	10800
Switched Power (max.)	10W	10
Switched Vdc/Vac (max.)	100V	200/140
Switched Current (max.)	0.5A	0.5A
Carry Current (max.)	0.5A	0.5A
Breakdown Voltage (min.)	110-150V	200-230
Contact Resist. (max.)	150m Ω	150
Contact Capacit. (max.)	0.5pF	0.3
Insulation Resist. (min.)	10 <sup>6</sup>	10 <sup>12</sup>
Mould Case	Black Epoxy Resin	
Sealed technique	Black Epoxy Resin	
Work Temperature	-55~+230	
Installation	2 leads, Plug-in	