



Unit:mm

客户

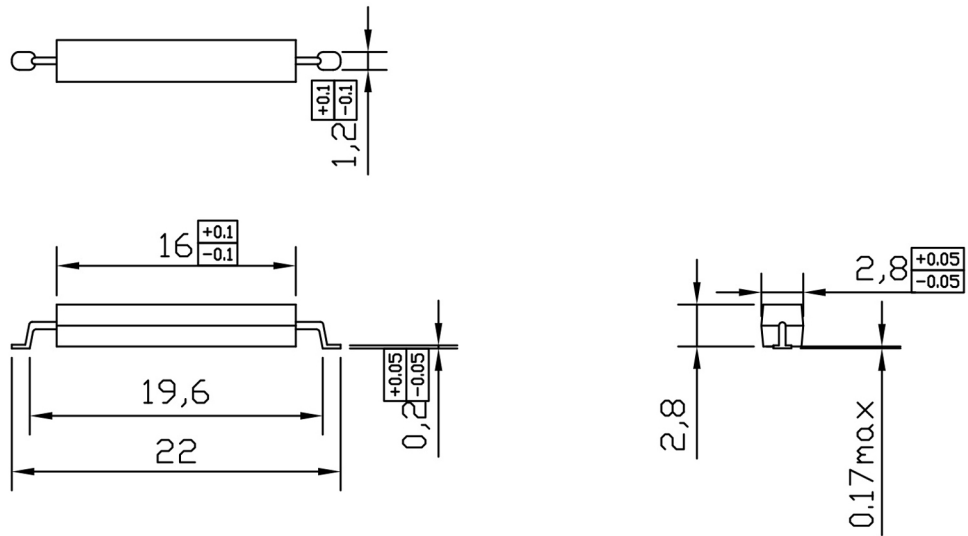

订购信息: Order Information

型号 Type	干簧管灵敏度 AT Range	触点方式 Contact Form
FRS-624SMDH	07-10	常开 (A)
FRS-624SMDH	10-15	常开 (A)
注: 卷盘包装: 2500个/盘 (2500pcs/reel)		

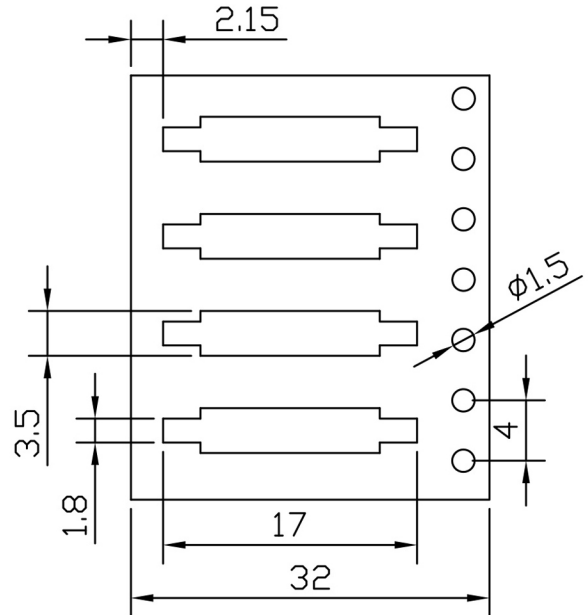

卷盘包装尺寸

Dimensions for tape and reel

技术参数 SPECIFICATION

开关触点 Contact Form		常开 (A)	TITLE		
最大开关功率 Contact Rating - max.	W	10	塑封贴片干簧管 Molded SMD Reed Switch		
最大开关电压 Switching Voltage - max.	V	200			
最大开关电流 Switching Current - max.	A	1	PART NO. FRS-624SMDH 系列		
最大载流电流 Carry Current - max.	A	0.5			
最大接触电阻 Contact Resistance - max.	mΩ	150	SCALE 2:1		
最小击穿电压 Breakdown Voltage - min.	V	160/220			
绝缘电阻 Insulation Resistance - min.	MΩ	10000	szkolas.1688.com		
工作温度 Operating Temperature	°C	-40~105			