



- G-Switch USB-C Specification:**
1. Current Rating: 5.0A
 2. Voltage: 100V AC
 3. Temperature Range: -55 °C ~ 85 °C
 4. Contact Resistance: 40 Megohms Max
 5. Insulation Resistance: 100 Megohms Min
 6. Insertion Force : 5N~20N
 7. Unmating Force: 8N~20N
 8. Durability: 10,000 Cycles

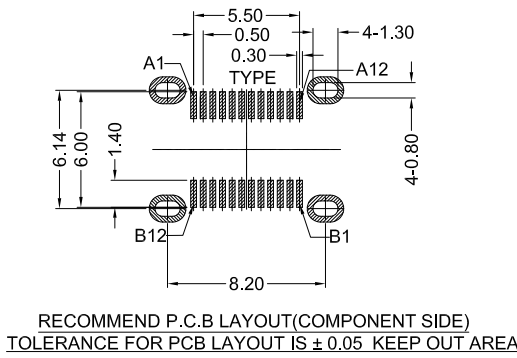

A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	A12
GND	TX1+	TX1-	VBUS	CC1	D+	D-	SBU1	VBUS	RX2-	RX2+	GND
GND	RX1+	RX1-	VBUS	SBU2	D-	D+	CC2	VBUS	TX2-	TX2+	GND
B12	B11	B10	B9	B8	B7	B6	B5	B4	B3	B2	B1
Item	Title	Material	Dispose		Q'TY						
1	Shell	SUS304	Ni:30u" Min.		1PCS						
2	GND Plate	SUS301			2PCS						
3	Mid Plate	SUS301			1PCS						
4	Contact	C7025	Mating Area: See P/IN Solder Tails: Matt Tin		2PCS						
5	InsertMolding	LCP E6808	UL 94V-0	Black	1PCS						
6	COVER	LCP E6808	UL 94V-0	Black	1PCS						

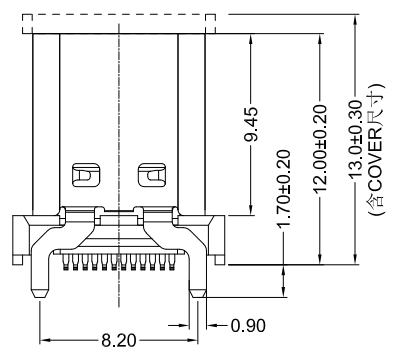

b-Switch 品赞科技®

G-Switch Electronic (HongKong) CO.,Ltd.

DESIGN Yu Chen	DATE 2022.07.18	Molde code:	
CHECKED	DATE	GT-USB-7028A	
APPROVED	DATE	REV.: X1	SCALE: 4:1
http://www.dg-switch.com		UNIT: mm	
TEL:0769-82388879		SIZE: A4	SHEET: 1/1

Unless otherwise specified, Tolerance:
 X. ±0.30
 X.xx ±0.20
 X.xxx ±0.15
 X.xxxx ±0.10
 Angles ±3°