


PS-5824DVX-4PN

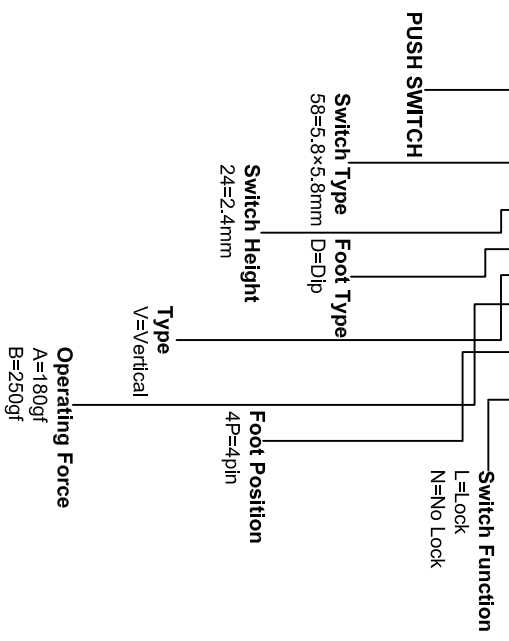

G-Switch Specification:
 Operating temperature range: -40°C to +85°C
 Rating: 0.5A, 24V DC
 Insulation resistance: 100MΩ min., 100V DC
 Dielectric strength: 250V AC for 1 min
 Contact resistance: 100mΩ max.
 Switch lifetime: 30,000Cycles

8	TERMINAL	BRASS	6	Ag PLATED
7	CASE	PPA	1	BLACK
6	LOCK PIN	SUS WIRE	1	NATURAL
5	SPRING	SUS WIRE	1	NATURAL
4	CONTACT	BRONZE	2	Ag PLATED
3	KNOB	PPA	1	WHITE
2	COVER	PPA	1	BLACK
NO.	PART NAME	MATERIAL	QTY	FINISHING



G-Switch 品豐科技

Unless otherwise specified, Tolerance:
 X: ±0.30
 X.X: ±0.20
 X.XX: ±0.15
 X.XXX: ±0.10
 Angles: ±3°

G-Switch Electronic (HongKong) CO., Ltd.

DESIGN: Feng? DATE: 2022.08.12
 CHECKED: DATE:
 APPROVED: DATE:
 Molde code: PS-5824DVX-4PN
 REV.: X1 SCALE: 4:1 UNIT: mm
 SIZE: A4 SHEET: 1/1

http://www.dg-switch.com
 TEL: 0769-82388879