

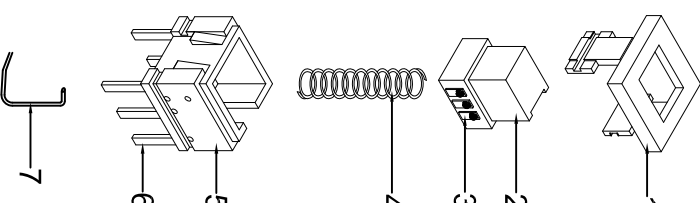
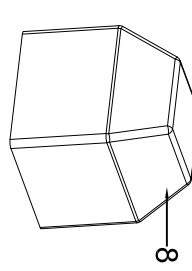


PUSH-ON:
2-3-5-6 Conduction

PUSH-OFF:
1-2-4-5 Conduction

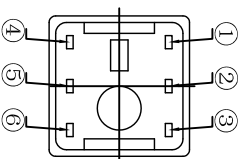


PS-6830DVX-6PL

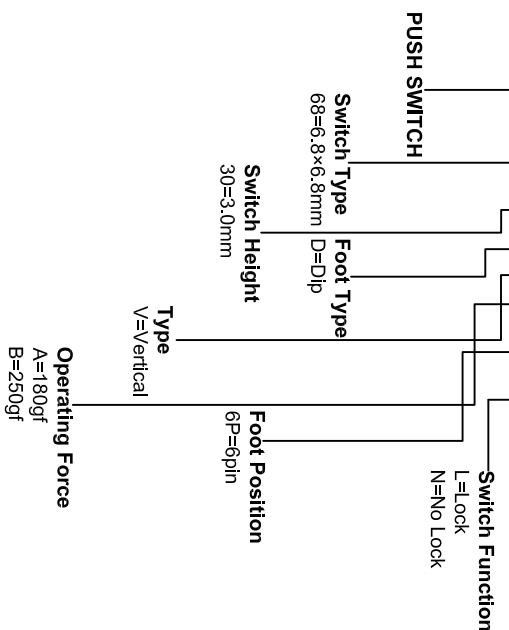

G-Switch Specification:
 Operating temperature range: -40°C to +85°C
 Rating: 0.5A, 24V DC
 Insulation resistance: 100MΩ min., 100V DC
 Dielectric strength: 250V AC for 1 min
 Contact resistance: 100mΩ max.
 Switch lifetime: 30,000Cycles

8	TERMINAL	BRASS	6	Ag PLATED
7	CASE	PPA	1	BLACK
6	LOCK PIN	SUS WIRE	1	NATURAL
5	SPRING	SUS WIRE	1	NATURAL
4	CONTACT	BRONZE	2	Ag PLATED
3	KNOB	PPA	1	WHITE
2	COVER	PPA	1	BLACK
1	PART NAME	MATERIAL	QTY	FINISHING

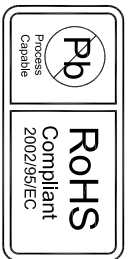

Unless otherwise specified, Tolerance:
 X .30
 X.X .20
 X.XX .15
 X.XXX .10
 Angles 3°

G-Switch Electronic (HongKong) CO., Ltd.

DESIGN	Feng?	DATE	2022.08.12	Mold code:	PS-6830DVX-6PL
CHECKED		DATE		REV.:	X1
APPROVED		DATE		SCALE:	4:1
http://www.dg-switch.com				SIZE:	A4
TEL: 0769-82388879				SHEET:	1/1
				UNIT:	mm