






Material

Insulator: Glass filled PBT, (UL 94V-0)
 Contact : Brass

Electrical Characteristics

Current rating: 3AMP
 Dielectric Withstanding Voltage: AC 500V for 1 Minute.
 Insulator Resistance: 1000MΩ Min. AT DC 500V.
 Contact Resistance: 20mΩ Max.
 Operating Temperature: -45 °C ~ +105 °C

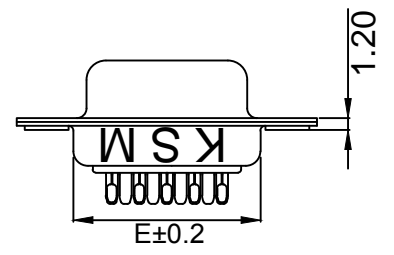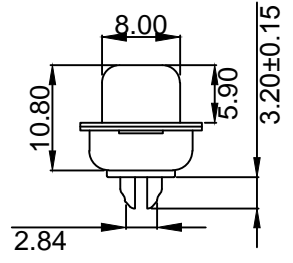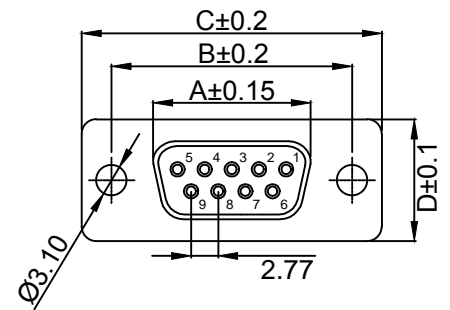

PIN	尺寸	A±0.15	B±0.2	C±0.2	D±0.1	E±0.2	D-SUB-*F			上海洲日电子有限公司 Shanghai Zhouri Electronics CO.,LTD					
							X.	±0.3	±5°	上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD					
D-SUB-9F		16.50	25.00	30.80	12.50	19.20	X.X	±0.2	±3°	20171018 A/0	TEL:86-21-34975176/51571121				
D-SUB-15F		24.80	33.30	39.20	12.50	27.80	X.XX	±0.15							
D-SUB-25F		38.55	47.10	53.10	12.50	41.20	201171018			ZR20171018-DB-62					
D-SUB-37F		54.90	63.50	69.44	12.50	57.30	201171018			物料编号	1:1	mm	图幅	A4	
							201171018			⊕		: 1 1			