



**Material**

Insulator: Glass filled PBT, (UL 94V-0)

Contact : Brass

**Electrical Characteristics**




Current rating: 3AMP

Dielectric Withstanding Voltage: AC 500V for 1 Minute.

Insulator Resistance: 1000MΩ Min. AT DC 500V.

Contact Resistance: 20mΩ Max.

Operating Temperature: -45 °C ~ +105 °C

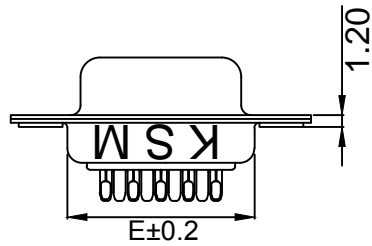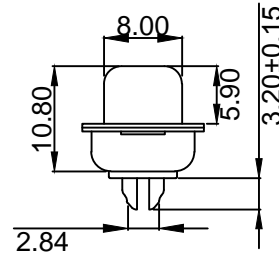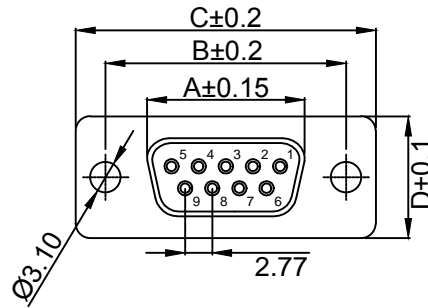

PIN	尺寸	A±0.15	B±0.2	C±0.2	D±0.1	E±0.2	D-SUB-*F			上海洲日电子有限公司 Shanghai Zhouri Electronics CO.,LTD			
							X.	±0.3	±5°	上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD			
D-SUB-9F		16.50	25.00	30.80	12.50	19.20				20171018 A/0			
D-SUB-15F		24.80	33.30	39.20	12.50	27.80	X.X	±0.2	±3°	ZR20171018-DB-62			
D-SUB-25F		38.55	47.10	53.10	12.50	41.20	X.XX	±0.15		TEL:86-21-34975176/51571121			
D-SUB-37F		54.90	63.50	69.44	12.50	57.30				物料编号 : 1 1 mm 图幅 A4			



: 1 1