






**Material**

Insulator: Glass filled PBT, (UL 94V-0)  
 Contact : Brass

**Electrical Characteristics**

Current rating: 3AMP  
 Dielectric Withstanding Voltage: AC 500V for 1 Minute.  
 Insulator Resistance: 1000MΩ Min. AT DC 500V.  
 Contact Resistance: 20mΩ Max.  
 Operating Temperature: -45 °C ~ +105 °C

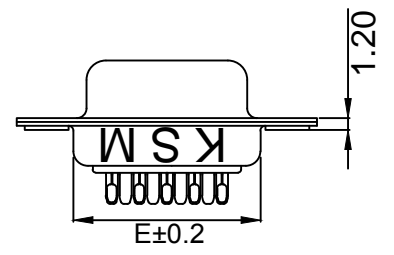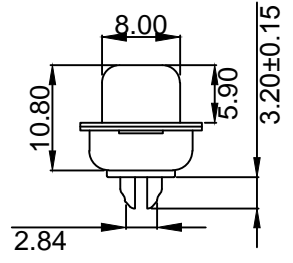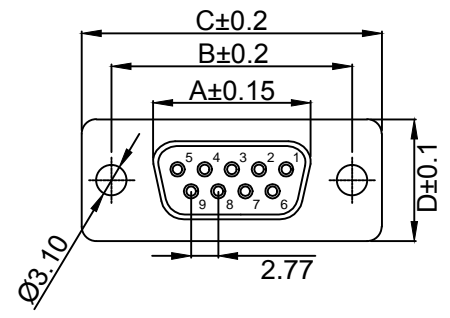

PIN	尺寸	A±0.15	B±0.2	C±0.2	D±0.1	E±0.2	D-SUB-*F			上海洲日电子有限公司 Shanghai Zhouri Electronics CO.,LTD				
							X.	±0.3	±5°	上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD				
D-SUB-9F		16.50	25.00	30.80	12.50	19.20	X.X	±0.2	±3°	20171018 A/0	TEL:86-21-34975176/51571121			
D-SUB-15F		24.80	33.30	39.20	12.50	27.80	X.XX	±0.15			ZR20171018-DB-62	1:1	mm	图幅
D-SUB-25F		38.55	47.10	53.10	12.50	41.20				201171018				
D-SUB-37F		54.90	63.50	69.44	12.50	57.30				201171018				
										物料编号				
										201171018				



: 1 1