

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1042660210](#)
Status: **Active**
Overview: [Lite-Trap and Mini Lite-Trap Connector System](#)
Description: Bottom-Entry Lite-Trap SMT Wire-to-Board Connector, Push-Button Type, 2 Circuits

Documents:

3D Model	Packaging Specification PK-104266-001-001 (PDF)
Drawing (PDF)	Datasheet (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-104266-001-001 (PDF)	

Agency Certification

UL E29179

General

Product Family	PCB Receptacles
Series	104266
Application	Wire-to-Board
Overview	Lite-Trap and Mini Lite-Trap Connector System
Product Name	Lite-Trap
UPC	889056499071

Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	Natural
Durability (mating cycles max)	25
Flammability	94V-0
Glow-Wire Capable	No
Material - Metal	Copper Alloy
Material - Plating Mating	Tin
Material - Resin	Liquid Crystal Polymer
Net Weight	0.910/g
Number of Rows	1
Orientation	Bottom Entry
PCB Retention	None
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	4.00mm
Plating min - Mating	0.800µm
Polarized to PCB	No
Temperature Range - Operating	-60° to +130°C
Termination Interface: Style	Surface Mount


Electrical

Current - Maximum per Contact	3.0A
Voltage - Maximum	320V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-104266-001-001
Product Specification	PS-104266-001-001
Sales Drawing	SD-104266-003-001

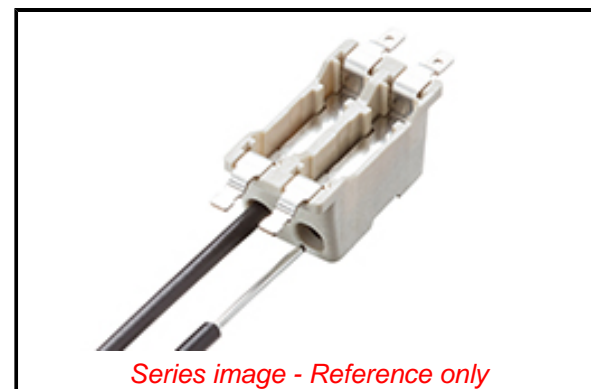

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ECHA_01_2020 (16
January 2020

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[104266 Series](#)