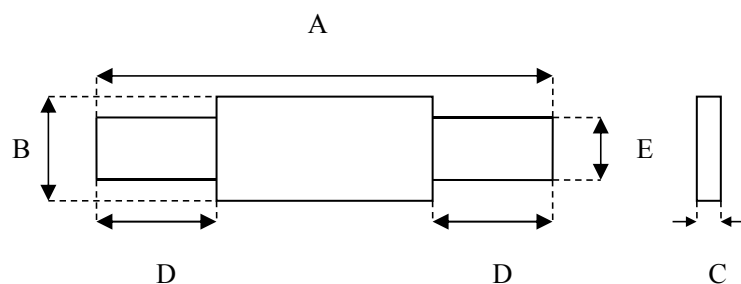



Product Dimensions(mm):


A:	21.9~24.5mm.
B:	3.0~3.6 mm.
C:	0.60~1.00 mm
D:	4.0~6.5mm
E:	2.3~3.2 mm

Lead materials: Quarter hard nickel, 0.11mm Nominal Thickness.

Tape materials: Polyester

Electrical Characteristics(25°C):


I_{max}	100 A	V_{max}	12 V
I_H	1.75A	I_T	3.80 A
Initial Resistance	29~51 mΩ	R_{1max}	100 mΩ

Test Conditions and Standards:

Item	Test Conditon	Standard
Initial Resistance	25°C	29~51 mΩ
I_H	25°C, 1.75 A, 60min	No Trip
Ttrip	25°C, 8.75A, 8V	≤5.0 s
Trip endurance	12V, 100A, 1hr	No arcing or burning

Operating Temperature: -40°C TO 85°C

Packaging: Bulk ,1000pcs per bag

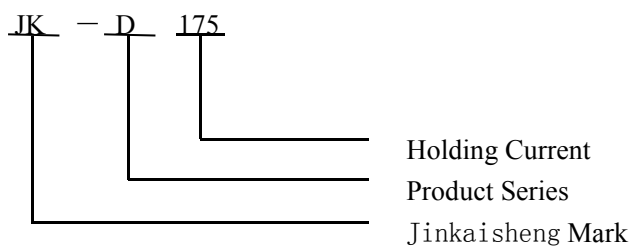Product marking:


20F,BUILDING 9C,BAONENG TECHNOLOGY PARK,QINGXIANG ROAD, LONGHUA, SHENZHEN, CHINA

Web Site: [http:// www.jksemi.com](http://www.jksemi.com)

TEL: 0755-26626670