
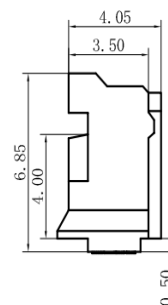
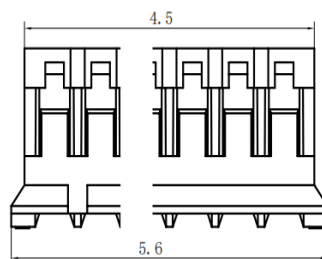
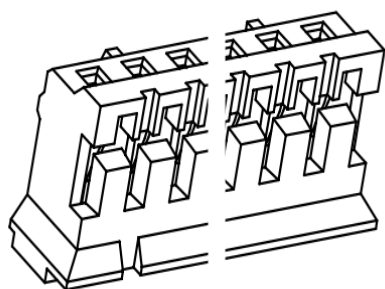
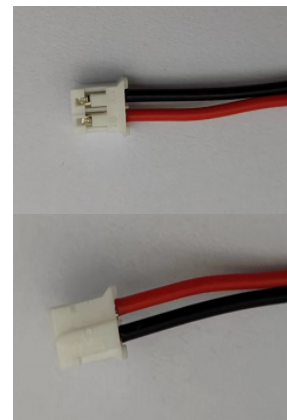


HX 2.0-2P ST 200mm 26AWG

2.0mm×2P双头同向插头, UL1007, 80 ,26AWG, 线长200mm

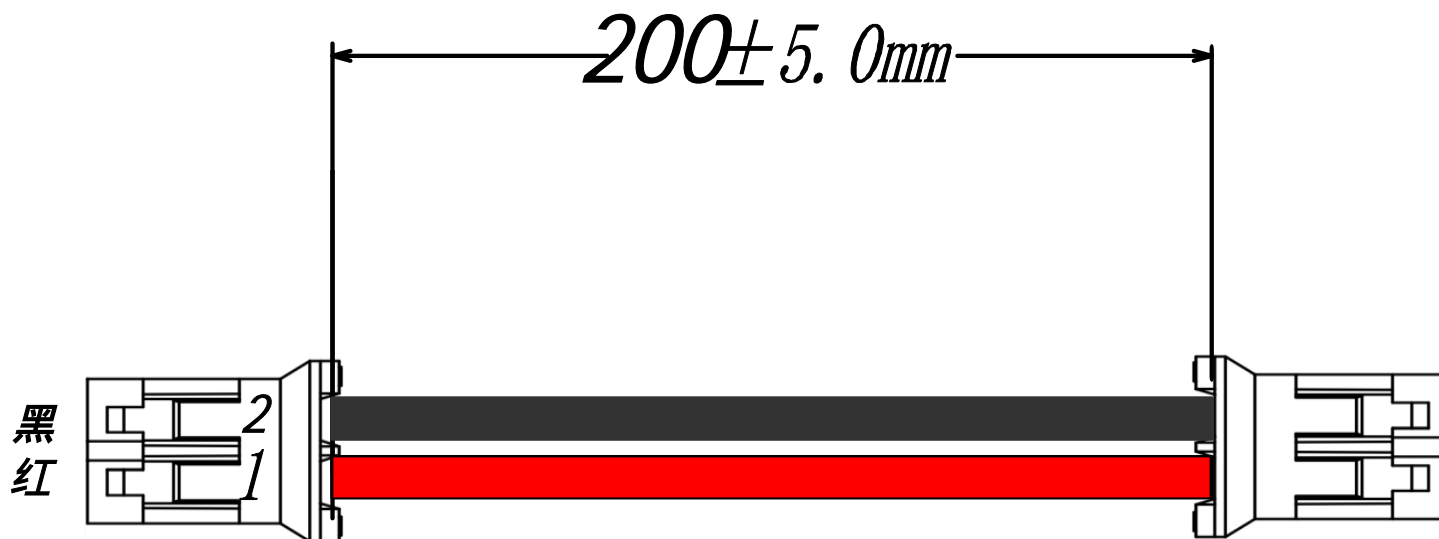

- 1. 极数 poles: 2 to 20P
- 2. 额定电流 Current rating: 2.0A AC, DC
- 3. 额定电压 Voltage rating: 100V AC, DC
- 4. 温度范围 Temperature range: -25. C to +85. C
- 5. 接触电阻 Contact resistance: $\leq 10m\Omega$
- 6. 绝缘电阻 Insulation resistance: $\geq 1000m\Omega$
- 7. 耐电压 Withstand voltage: 800V AC/minute
- 8. 适用线规 Applicable Wire: AWG #26
- 9. 适用基板厚度 Applicable PC board thickness: 1.6mm

 深圳市韩下电子有限公司	
日期: 2020-6-15	元件名称: HX 2.0-2P ST 200mm 26AWG
绘制: 李耀凤	
审核: 钟华华	
批准: 罗家金	
尺寸单位: mm	
第 1 页 共 1 页	