
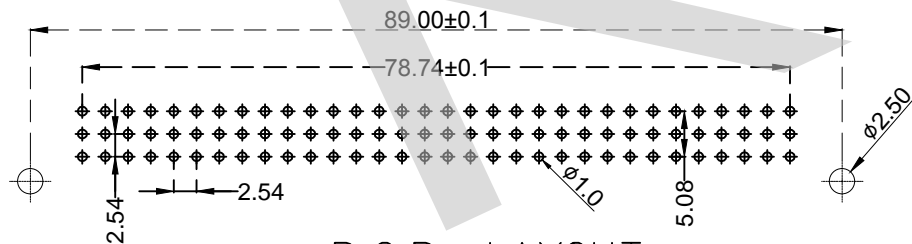
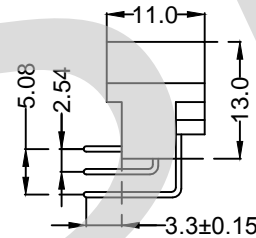
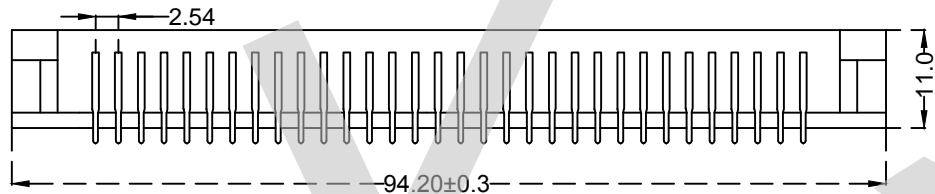


KSM 凯司玛 9001-11961C

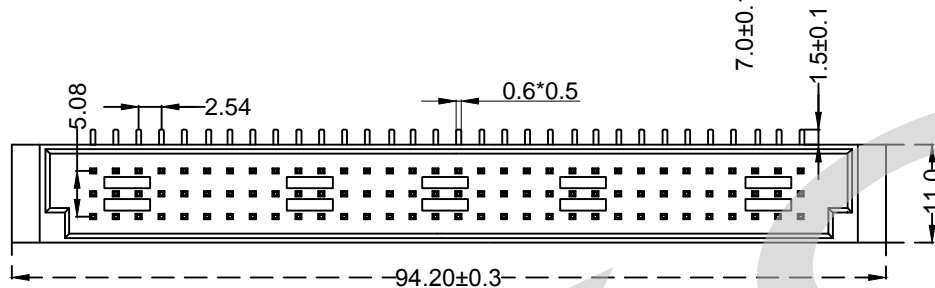

P.C.B LAYOUT

Material材料

Insulator 塑胶: 30%Glass filled PBT, (UL 94V-0)

Contact 端子: Brass 黄铜

Electrical Characteristics 电气特性

Current rating 额定电流: 1.5AMP

Dielectric Withstanding Voltage 耐压: AC 1000V for 1Minute.

Insulator Resistance 绝缘电阻: 1000MΩ Min. AT DC 500V.

Contact Resistance 接触电阻: 30MΩ Max. AT DC 100mA.

Operating Temperature 工作温度: -40℃~+105℃

未注公差尺寸			KSM-9001-11961C		上海洲日电子有限公司		
公差			396		Shanghai Zhouri Electronics CO.,LTD		
尺寸	长度	角度	版本号	20171018 A/0	上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD		
X.	±0.3	±5°					
X.X	±0.2	±3°					
X.XX	±0.15		图编号	ZR20171018-49	TEL:86-21-34975176/51571121		
绘图	周元金	201171018	物料编号	110663	1:1	mm	图幅 A4
审核	张海娜	201171018					
核准	章妹	20181113					